

3-Point Internal Micrometer

Holtest

Item number: 368-871

Images




Description

A non-digital Mitutoyo bore gauge. Hardened steel contact faces. A ratchet stop guarantees repeatable measurement.

Features

Inch-Metric:	Inch
Digital/Analog:	Analog
Range:	2,5 - 3 "
Graduation:	≤ 0.5": 0.0001", >0.5": 0.0002"
Scale:	Thimble and sleeve satin chrome finish, Up to 12 mm : Ø 17 mm Over 12 mm : Ø 23 mm
Measuring spindle:	Spindle pitch 0,635 mm
Measuring face:	hardened steel Taper: hardened steel
Measuring method:	3-point
Delivered:	Including box, spanner, hex wrench, certificate of inspection, without setting ring
Mass:	450 g

Dimensions

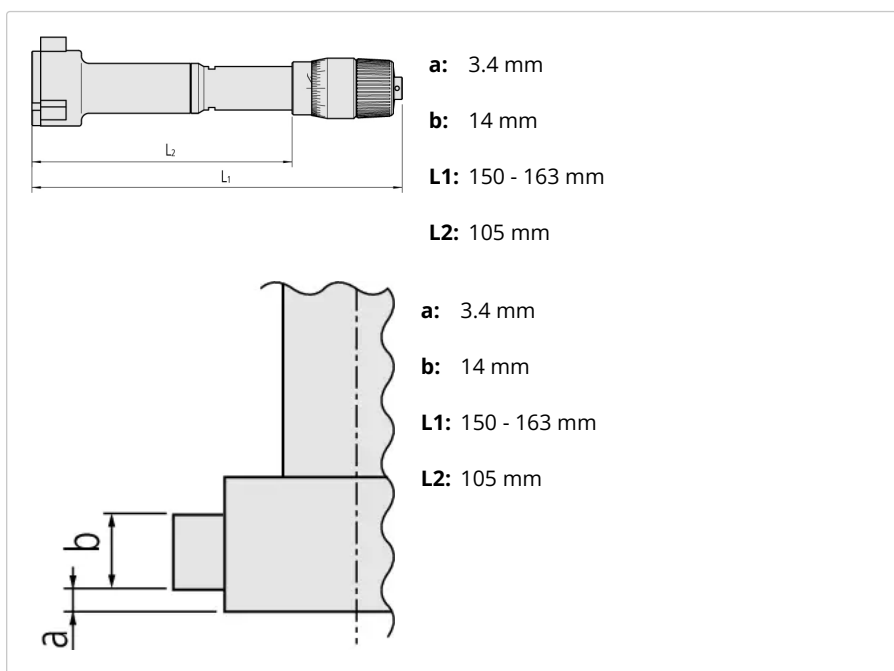

Accessories

Optional accessories:



**Holtest, Borematic Extension
150mm**

for 50-300mm Measuring Range
Art No. 952623
Suggested retail price: 216.00 €*



Setting Ring 2,5"

Steel
Art No. 177-315
Suggested retail price: 344.00 €*



Setting Ring 3"

Steel
Art No. 177-317
Suggested retail price: 365.00 €*