

# 3-Point Internal Micrometer

## Holtest

Item number: 368-875

### Images




### Description

A non-digital Mitutoyo bore gauge. Hardened steel contact faces. A ratchet stop guarantees repeatable measurement.

### Features

<b>Inch-Metric:</b>	Inch
<b>Digital/Analog:</b>	Analog
<b>Range:</b>	5 - 6 "
<b>Graduation:</b>	≤ 0.5": 0.0001", >0.5": 0.0002"
<b>Scale:</b>	Thimble and sleeve satin chrome finish, Up to 12 mm : Ø 17 mm Over 12 mm : Ø 23 mm
<b>Measuring spindle:</b>	Spindle pitch 0,635 mm
<b>Measuring face:</b>	hardened steel Taper: hardened steel
<b>Measuring method:</b>	3-point
<b>Delivered:</b>	Including box, spanner, hex wrench, certificate of inspection, without setting ring
<b>Mass:</b>	1110 g

### Dimensions

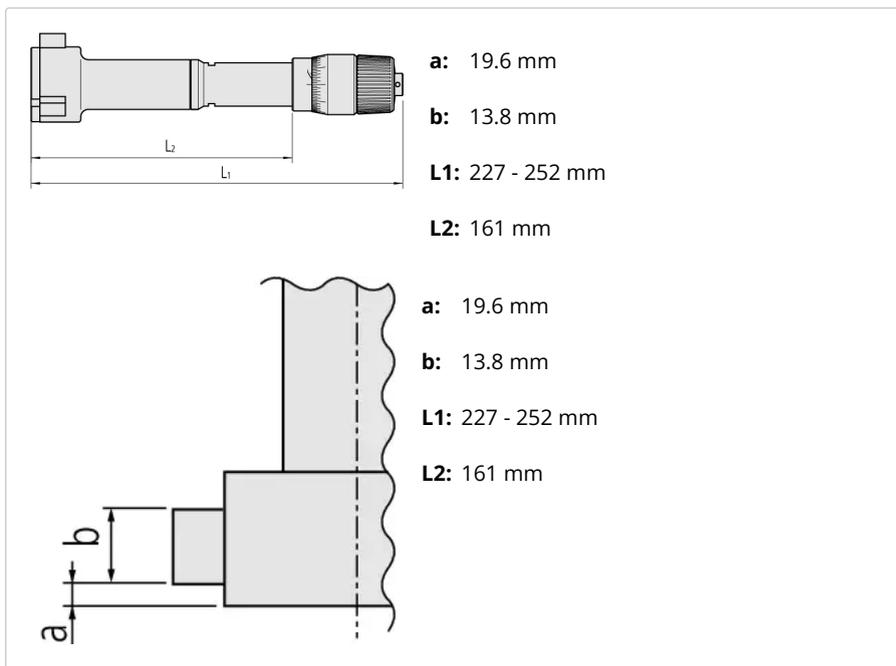

Optional accessories:



**Holtest, Borematic Extension  
150mm**

for 50-300mm Measuring Range  
Art No. 952623  
Suggested retail price: 216.00 €\*



**Setting Ring 5"**

Steel  
Art No. 177-299  
Suggested retail price: 989.00 €\*



**Setting Ring 6"**

Steel  
Art No. 177-301  
Suggested retail price: 1,061.00 €\*