

3-Point Internal Micrometer

Holtest

Item number: 368-877

Images




Description

A non-digital Mitutoyo bore gauge. Hardened steel contact faces. A ratchet stop guarantees repeatable measurement.


Features

Inch-Metric:	Inch
Digital/Analog:	Analog
Range:	7 - 8 "
Graduation:	≤ 0.5": 0.0001", >0.5": 0.0002"
Scale:	Thimble and sleeve satin chrome finish, Up to 12 mm : Ø 17 mm Over 12 mm : Ø 23 mm
Measuring spindle:	Spindle pitch 0,635 mm
Measuring face:	hardened steel Taper: hardened steel
Measuring method:	3-point
Delivered:	Including box, spanner, hex wrench, certificate of inspection, without setting ring
Mass:	1300 g

Dimensions

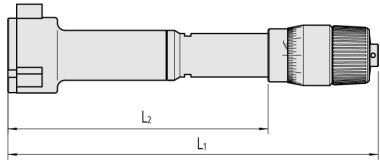

a: 19.6 mm
b: 13.8 mm
L1: 227 - 252 mm
L2: 161 mm

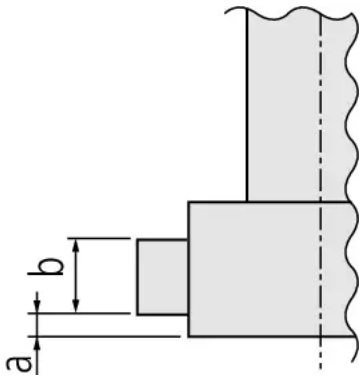

a: 19.6 mm
b: 13.8 mm
L1: 227 - 252 mm
L2: 161 mm

Accessories

Optional accessories:



**Holtest, Borematic Extension
150mm**

for 50-300mm Measuring Range
 Art No. 952623
 Suggested retail price: 216.00 €*



Setting Ring 7"

Steel
 Art No. 177-303
 Suggested retail price: 1,516.00 €*



Setting Ring 8"

Steel
 Art No. 177-305
 Suggested retail price: 1,929.00 €*

