

3-Point Internal Micrometer

Holtest

Item number: 368-878

Images



Description

A non-digital Mitutoyo bore gauge. Hardened steel contact faces. A ratchet stop guarantees repeatable measurement.

Features

Digital/Analog:	Analog
Inch-Metric:	Inch
Range:	8 - 9 "
Graduation:	≤ 0.5 " : 0.0001", >0.5 " : 0.0002"
Scale:	Thimble and sleeve satin chrome finish, Up to 12 mm : \varnothing 17 mm Over 12 mm : \varnothing 23 mm
Measuring spindle:	Spindle pitch 0,635 mm
Measuring face:	hardened steel Taper: hardened steel

Measuring method:

3-point


Delivered:

Including box, spanner, hex wrench,
certificate of inspection, without setting
ring

Mass:

1420 g

Dimensions

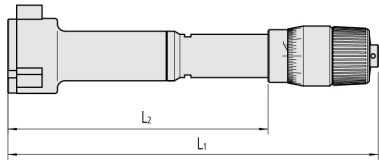


a: 19.6 mm

b: 13.8 mm

L1: 227 - 252 mm

L2: 161 mm

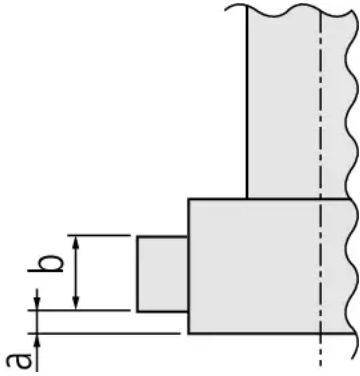

a: 19.6 mm

b: 13.8 mm

L1: 227 - 252 mm

L2: 161 mm

Accessories

Optional accessories:



Holtest, Borematic Extension 150mm

for 50-300mm Measuring Range

Art No. 952623

Suggested retail price: 222.00 €*



Setting Ring 8"

Steel

Art No. 177-305

Suggested retail price: 1,929.00 €*



Setting Ring 9"

Steel

Art No. 177-307

Suggested retail price: 2,177.00 €*
