

3-Point Internal Micrometer

Holtest

Item number: 368-879

Images



Description

A non-digital Mitutoyo bore gauge. Hardened steel contact faces. A ratchet stop guarantees repeatable measurement.

Features


| | |
|---------------------------|------------------------------------------------------------------------------------------------------------------|
| Inch-Metric: | Inch |
| Digital/Analog: | Analog |
| Range: | 9 - 10 " |
| Graduation: | $\leq 0.5"$: 0.0001", $>0.5"$: 0.0002" |
| Scale: | Thimble and sleeve satin chrome finish, Up to 12 mm : \varnothing 17 mm Over 12 mm : \varnothing 23 mm |
| Measuring spindle: | Spindle pitch 0,635 mm |
| Measuring face: | hardened steel Taper: hardened steel |

Measuring method: 3-point

Delivered: Including box, spanner, hex wrench,
certificate of inspection, without setting
ring

Mass: 1540 g

Dimensions

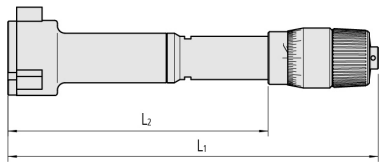


a: 19.6 mm

b: 13.8 mm

L1: 227 - 252 mm

L2: 161 mm

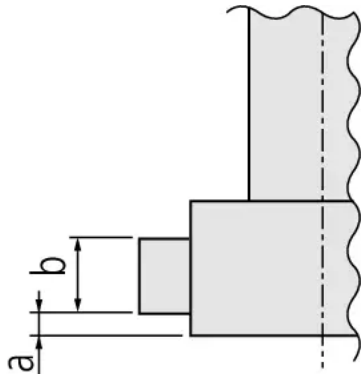

a: 19.6 mm

b: 13.8 mm

L1: 227 - 252 mm

L2: 161 mm

Accessories

Optional accessories:



Holtest, Borematic Extension 150mm

for 50-300mm Measuring Range

Art No. 952623

Suggested retail price: 216.00 €*



Setting Ring 9"

Steel

Art No. 177-307

Suggested retail price: 2,177.00 €*



Setting Ring 10"

Steel

Art No. 177-309

Suggested retail price: 2,364.00 €*
