


## 3-Point Internal Micrometer

### Holtest

Item number: 368-880

#### Images

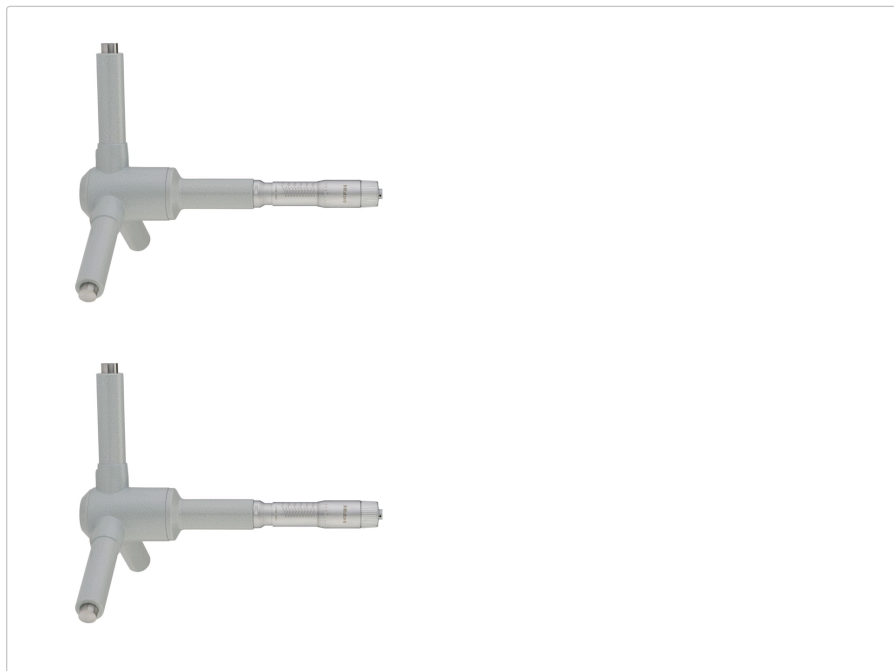


#### Description

A non-digital Mitutoyo bore gauge. Hardened steel contact faces. A ratchet stop guarantees repeatable measurement.

#### Features

<b>Inch-Metric:</b>	Inch
<b>Digital/Analog:</b>	Analog
<b>Range:</b>	10 - 11 "
<b>Graduation:</b>	$\leq 0.5"$ : 0.0001", $>0.5"$ : 0.0002"
<b>Scale:</b>	Thimble and sleeve satin chrome finish, Up to 12 mm : $\varnothing$ 17 mm Over 12 mm : $\varnothing$ 23 mm
<b>Measuring spindle:</b>	Spindle pitch 0,635 mm
<b>Measuring face:</b>	hardened steel Taper: hardened steel
<b>Measuring method:</b>	3-point
<b>Delivered:</b>	Including box, spanner, hex wrench, certificate of inspection, without setting ring
<b>Mass:</b>	1690 g

#### Dimensions

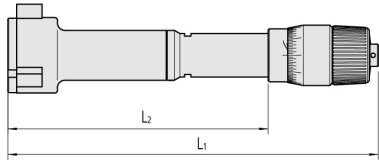


**a:** 19.6 mm

**b:** 13.8 mm

**L1:** 227 - 252 mm

**L2:** 161 mm

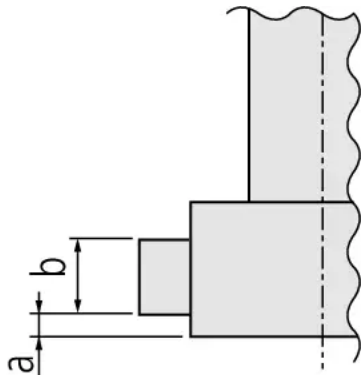

**a:** 19.6 mm

**b:** 13.8 mm

**L1:** 227 - 252 mm

**L2:** 161 mm

## Accessories

### Optional accessories:



### Holtest, Borematic Extension 150mm

for 50-300mm Measuring Range

Art No. 952623

Suggested retail price: 216.00 €\*



### Setting Ring 10"

Steel

Art No. 177-309

Suggested retail price: 2,364.00 €\*



### Setting Ring 11"

Steel

Art No. 177-311

Suggested retail price: 2,723.00 €\*

