


3-Point Internal Micrometer

Holtest

Item number: 368-881

Images

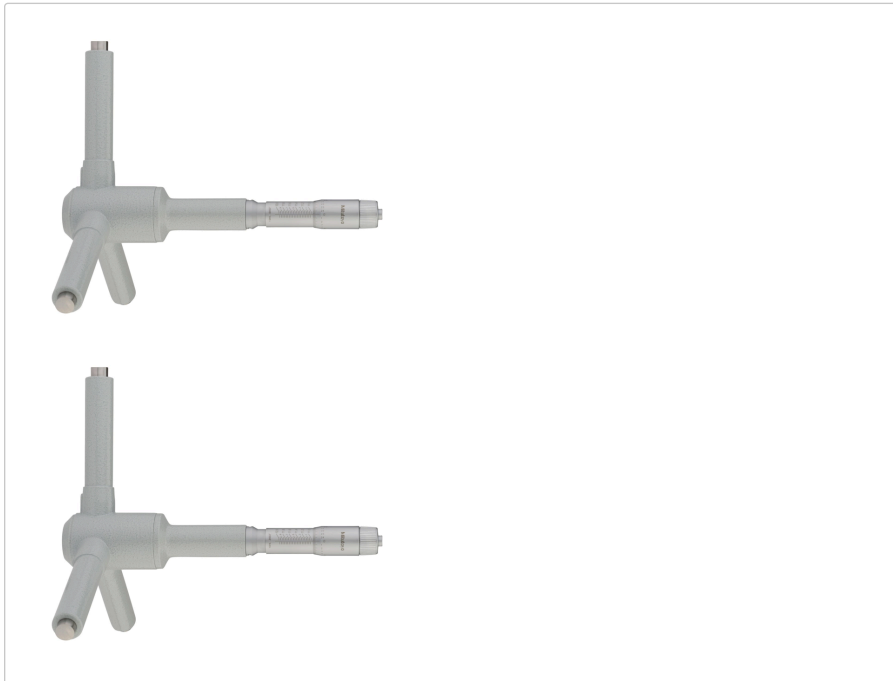


Description

A non-digital Mitutoyo bore gauge. Hardened steel contact faces. A ratchet stop guarantees repeatable measurement.

Features

Inch-Metric:	Inch
Digital/Analog:	Analog
Range:	11 - 12 "
Graduation:	≤ 0.5 " : 0.0001" , >0.5 " : 0.0002"
Scale:	Thimble and sleeve satin chrome finish, Up to 12 mm : \varnothing 17 mm Over 12 mm : \varnothing 23 mm
Measuring spindle:	Spindle pitch 0,635 mm
Measuring face:	hardened steel Taper: hardened steel
Measuring method:	3-point
Delivered:	Including box, spanner, hex wrench, certificate of inspection, without setting ring
Mass:	1860 g

Dimensions

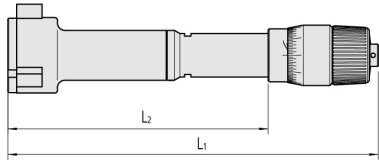


a: 19.6 mm

b: 13.8 mm

L1: 227 - 252 mm

L2: 161 mm

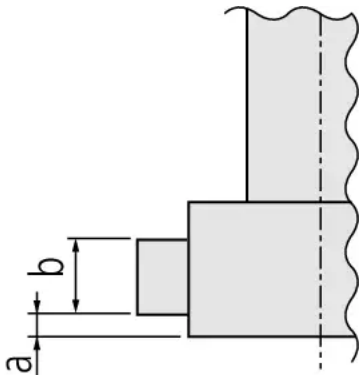

a: 19.6 mm

b: 13.8 mm

L1: 227 - 252 mm

L2: 161 mm

Accessories

Optional accessories:



Holtest, Borematic Extension 150mm

for 50-300mm Measuring Range

Art No. 952623

Suggested retail price: 216.00 €*



Setting Ring 11"

Steel

Art No. 177-311

Suggested retail price: 2,723.00 €*



Setting Ring 12"

Steel

Art No. 177-313

Suggested retail price: 3,329.00 €*

