


## 3-Point Internal Micrometer

### Holtest Set

Item number: 368-997

#### Images

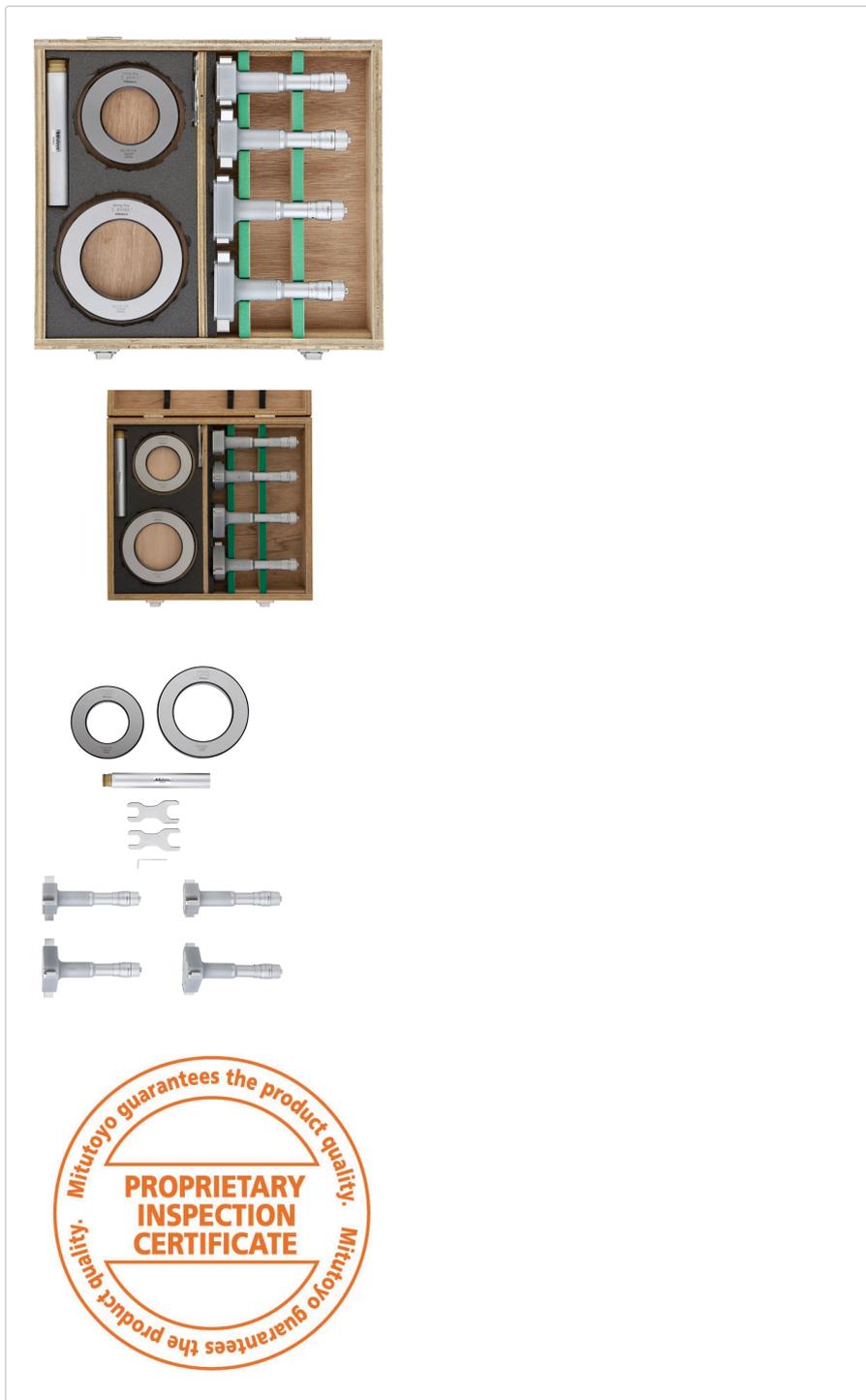

#### Description

A Mitutoyo internal micrometer set consisting of individual gauges, the appropriate setting rings and an extension tube for depth measurement applications. Contact surfaces made of hardened steel. A ratchet guarantees repeatable measurement.

#### Features

<b>Inch-Metric:</b>	Inch
<b>Digital/Analog:</b>	Analog
<b>Range:</b>	2 - 4 "
<b>Graduation:</b>	$\leq 0.5$ " : 0.0001", $>0.5$ " : 0.0002"

<b>Individual ranges:</b>	2-2.5", 2.5-3", 3-3.5", 3.5-4"
<b>Scale:</b>	Thimble and sleeve satin chrome finish, Up to 12 mm : Ø 17 mm Over 12 mm : Ø 23 mm
<b>Measuring spindle:</b>	Spindle pitch 0,635 mm
<b>Measuring face:</b>	Hardened steel taper: hardened steel
<b>Measuring method:</b>	3-point
<b>Models included:</b>	368-870 / 368-871 / 368-872 / 368-873
<b>Setting rings included:</b>	ø2.5" (177-315) ø3.5" (177-319)
<b>Delivered:</b>	Including box, spanner (2 pcs.), hex wrench, certificate of inspection, setting rings (2 pcs.), extension rod
<b>Mass:</b>	2080 g

## Accessories

### Optional accessories:



#### Holtest, Borematic Extension 150mm

for 12-20mm Measuring Range  
Art No. 952621  
Suggested retail price: 120.00 €\*



#### Holtest, Borematic Extension 150mm

for 20-50mm Measuring Range  
Art No. 952622  
Suggested retail price: 136.00 €\*



#### Holtest, Borematic Extension 150mm

for 50-300mm Measuring Range  
Art No. 952623  
Suggested retail price: 216.00 €\*

