


## Digital Disc Micrometer

Item number: 369-350-30

### Images

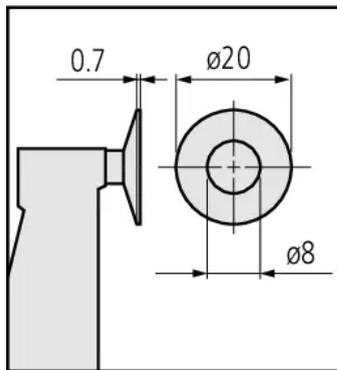

### Description

This Digimatic Disc Micrometer allows you to measure a range of different materials. It offers you the following benefits:


- Non-rotating spindle and disc-shaped measuring surfaces.
- Measuring the root tangent length of spur and helical gears
- Measurable range of gear pitch: 0,5-6 module
- Suitable for measuring felt, rubber, cardboard, fabric etc.

### Features

|                                      |   |
|--------------------------------------|---|
| <b>Digital/Analog:</b>               | Digital   |
| <b>Inch-Metric:</b>                  | Inch/Metric                                       |
| <b>Range:</b>                        | 0 - 1 "   |
| <b>Digital step:</b>                 | 0.00005"/0.001 mm                                 |
| <b>Max. Permissible Error J MPE:</b> | ±0.0002"  |
| <b>Delivered:</b>                    | Including box, spanner, 1 SR44 battery            |
| <b>Parallelism:</b>                  | 0.0002"   |
| <b>Display:</b>                      | LCD, character height 7.5 mm                      |
| <b>Measuring face:</b>               | Hardened steel, micro-lap finish                  |
| <b>Measuring spindle:</b>            | With spindle lock, ø6,35 mm, spindle pitch 0,5 mm |

|  |  |
|--|--|
| <b>Scale:</b>                                | Thimble and sleeve satin chrome finish, ø18 mm |
| <b>Data output:</b>                          | Yes  |
| <b>Measuring force:</b>                      | 3 - 8 N  |
| <b>Power supply:</b>                         | 1 battery SR-44                                |
| <b>Battery life:</b>                         | Approx. 2.4 years                              |
| <b>Measurable module:</b>                    | 0.5 - 6 mm                                     |
| <b>ORIGIN:</b>                               | Yes  |
| <b>ABS / INC (INC ZERO):</b>                 | Yes  |
| <b>Auto Power OFF after 20 min. non use:</b> | Yes  |
| <b>Low voltage alarm:</b>                    | Yes  |
| <b>Function lock:</b>                        | Yes  |
| <b>HOLD:</b>                                 | Yes  |
| <b>Mass:</b>                                 | 340 g  |

### Dimensions

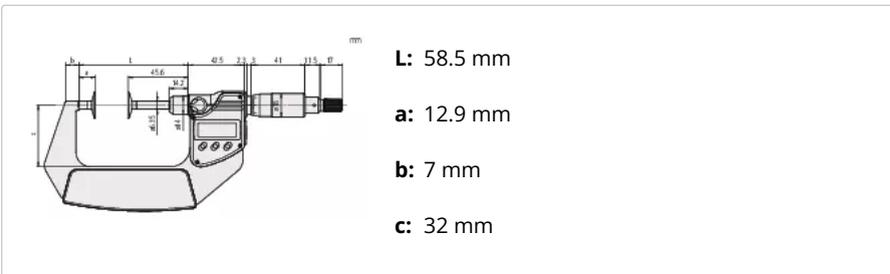

### Accessories

Optional accessories:



#### Micrometer Stand, 45° Angle Type

for Micrometer 0-50mm/0-2"  
 Art No. 156-105-10  
 Suggested retail price: 58.00 €\*

Promotion!



#### Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"  
 Art No. 156-101-10  
**Promo price: 56.00 €\***   
~~Suggested retail price: 70.00 €\*~~

Promotion!



## Connection Unit for IP Caliper, Micrometer

with Data Button for U-WAVE fit, U-WAVE fit Bluetooth

Art No. 02AZF310

Promo price: **76.00 €\***

Suggested retail price: ~~110.00 €\*~~

Promotion!



## USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, with Data Button IP Micrometer Type

Art No. 06AFM380B

Promo price: **111.00 €\***

Suggested retail price: ~~141.00 €\*~~

## Digimatic Cable with Data Button IP Type



1 m, Micrometer Type

Art No. 05CZA662

Suggested retail price: 105.00 €\*

## Digimatic Cable with Data Button IP Type



2 m, Micrometer Type

Art No. 05CZA663

Suggested retail price: 107.00 €\*

Promotion!



## U-WAVE fit, IP67 Type

Wireless Transmitter for Micrometer/Indicator

Art No. 264-622

Promo price: **129.00 €\***

Suggested retail price: ~~185.00 €\*~~

Promotion!



### U-WAVE fit, Buzzer Type

Wireless Transmitter for  
Micrometer/Indicator

Art No. 264-623

Promo price: **129.00 €\***

Suggested retail price: ~~185.00 €\*~~

Promotion!



### U-WAVE fit Bluetooth, IP67 Type

Wireless Transmitter for  
Micrometer/Indicator

Art No. 264-626

Promo price: **129.00 €\***

Suggested retail price: ~~185.00 €\*~~

Promotion!



### U-WAVE fit Bluetooth, Buzzer Type

Wireless Transmitter for  
Micrometer/Indicator

Art No. 264-627

Promo price: **129.00 €\***

Suggested retail price: ~~185.00 €\*~~

Promotion!

Mitutoyo

MiCAT

the standard in world  
metrology software  
MeasurLink

### USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available  
Online)

Art No. 06AGR543

Promo price: **268.00 €\***

Suggested retail price: ~~340.00 €\*~~



#### Spare parts

Consumable spares:



## Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 7.00 €\*  

---