


Digital Disc Micrometer QuickMike, IP65

Item number: 369-412-20

Images

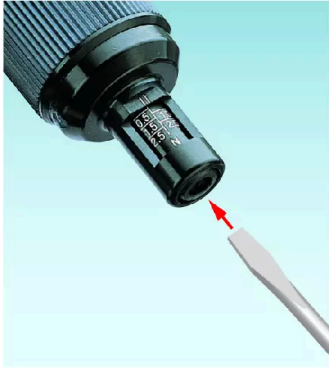

ABSOLUTE®
IP65

Description

The ABSOLUTE Digimatic Disc Micrometer Quickmike allows you to measure with a fast spindle feed of 10 mm per thimble rotation.

It offers you the following benefits:


- Suitable for measuring felt, rubber, cardboard, fabric etc.
- Suitable to measure "root tangent length" of spur gears and helical gears.
- With a non-rotating spindle and disc-shaped measuring surface.
- Measuring force is adjustable for various kinds of workpieces (series 227)

Features

Digital/Analog:	Digital
Inch-Metric:	Metric
Range:	25 - 55 mm
Digital step:	0,001 mm
Max. Permissible Error J MPE:	±4 µm
Delivered:	Including box, setting standard, 1 SR44 battery
Flatness:	1 µm
Parallelism:	4 µm
Display:	LCD, character height 10 mm

Measuring face:	Hardened steel, micro-lap finish
Measuring spindle:	ø6,35 mm, non-rotating, spindle feed 10 mm
Data output:	Yes
Measuring force:	3 - 8 N
Power supply:	1 battery SR-44
Battery life:	Approx. 5 years
Measurable module:	0.5 - 6 mm
ON/OFF:	Yes
ORIGIN:	Yes
ABS / INC (INC ZERO):	Yes
Low voltage alarm:	Yes
HOLD:	Yes
Mass:	490 g

Dimensions

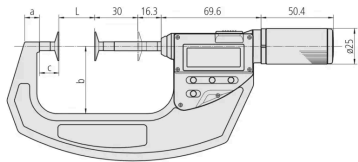

L: 25 mm

a: 10.3 mm

b: 47 mm

c: 13.5 mm

Accessories

Optional accessories:



Micrometer Stand, 45° Angle Type

for Micrometer 0-50mm/0-2"

Art No. 156-105-10

Suggested retail price: 58.00 €*

Promotion!



Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"

Art No. 156-101-10

Promo price: **56.00 €***

Suggested retail price: 70.00 €*

Promotion!



Connection Cable B for U-WAVE

with Data Button for IP Micrometer Type
Art No. 02AZD790B

Promo price: **76.00 €***
Suggested retail price: ~~110.00 €*~~

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, with Data Button IP Micrometer Type
Art No. 06AFM380B

Promo price: **111.00 €***
Suggested retail price: ~~141.00 €*~~

Digimatic Cable with Data Button IP Type



1 m, Micrometer Type
Art No. 05CZA662
Suggested retail price: 105.00 €*

Digimatic Cable with Data Button IP Type



2 m, Micrometer Type
Art No. 05CZA663
Suggested retail price: 107.00 €*

Promotion!



U-WAVE-T, IP67 Type

Wireless Transmitter
Art No. 02AZD730G

Promo price: **129.00 €***
Suggested retail price: ~~187.00 €*~~

Promotion!



U-WAVE-T, Buzzer Type

Wireless Transmitter

Art No. 02AZD880G

Promo price: **129.00 €***

Suggested retail price: ~~187.00 €*~~

Standard accessories:



Micrometer Setting Standard

Length: 25mm

Art No. 167-101

Suggested retail price: **33.00 €***

Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: **7.00 €***