
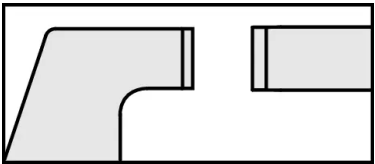


## Digital Sheet Metal Micrometer IP65

Item number: 389-252-30

### Images

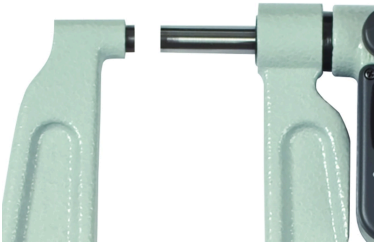

Dust- and  
Waterproof  
IP65

www.tuv.com  
ID 4011207400




### Description

This Digimatic Sheet Metal Micrometer is designed with a deep frame, for measuring the thickness of sheet material.

### Features

<b>Model:</b>	PMU150-50MX
<b>Digital/Analog:</b>	Digital
<b>Inch-Metric:</b>	Metric
<b>Range:</b>	25 - 50 mm
<b>Digital step:</b>	0,001 mm
<b>Max. Permissible Error J MPE:</b>	±4 µm
<b>Delivered:</b>	Including box, spanner, setting standard, 1 SR44 battery
<b>Flatness:</b>	0,6 µm
<b>Parallelism:</b>	3 µm
<b>Display:</b>	LCD, character height 7.5 mm
<b>Measuring face:</b>	Carbide-tipped, micro-lap finish
<b>Anvil / Spindle:</b>	Type A, flat/flat
<b>Measuring spindle:</b>	With spindle lock, ø6,35 mm, spindle pitch 0,5 mm
<b>Scale:</b>	Thimble and sleeve satin chrome finish, ø18 mm
<b>Data output:</b>	Yes
<b>Measuring force:</b>	3 - 8 N
<b>Power supply:</b>	Battery SR-44
<b>Battery life:</b>	Approx. 2.4 years, Approx. 1.8 years (389-514)
<b>ORIGIN:</b>	Yes
<b>ABS / INC (INC ZERO):</b>	Yes
<b>Auto Power OFF after 20 min. non use:</b>	Yes
<b>Low voltage alarm:</b>	Yes
<b>Function lock:</b>	Yes
<b>HOLD:</b>	Yes
<b>2 x PRESET:</b>	Yes
<b>Throat depth:</b>	160 mm
<b>Mass:</b>	920 g

## Dimensions

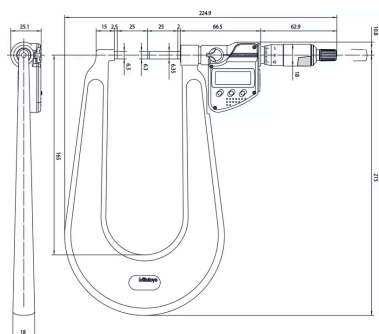

Optional accessories:

Promotion!



### Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"  
Art No. 156-101-10

Promo price: **56.00 €\***   
Suggested retail price: ~~70.00 €\*~~

Promotion!



### Connection Unit for IP Caliper, Micrometer

with Data Button for U-WAVE fit, U-WAVE fit Bluetooth  
Art No. 02AZF310

Promo price: **76.00 €\***   
Suggested retail price: ~~110.00 €\*~~

Promotion!



### USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, with Data Button IP Micrometer Type  
Art No. 06AFM380B

Promo price: **111.00 €\***   
Suggested retail price: ~~141.00 €\*~~



### Digimatic Cable with Data Button IP Type

1 m, Micrometer Type  
Art No. 05CZA662  
Suggested retail price: 105.00 €\*



### Digimatic Cable with Data Button IP Type

2 m, Micrometer Type  
Art No. 05CZA663  
Suggested retail price: 107.00 €\*

Promotion!



### U-WAVE fit, IP67 Type

Wireless Transmitter for  
Micrometer/Indicator  
Art No. 264-622

Promo price: **129.00 €\***  
Suggested retail price: ~~185.00 €\*~~

Promotion!



### U-WAVE fit, Buzzer Type

Wireless Transmitter for  
Micrometer/Indicator  
Art No. 264-623

Promo price: **129.00 €\***  
Suggested retail price: ~~185.00 €\*~~

Promotion!



### U-WAVE fit Bluetooth, IP67 Type

Wireless Transmitter for  
Micrometer/Indicator  
Art No. 264-626

Promo price: **129.00 €\***  
Suggested retail price: ~~185.00 €\*~~

Promotion!



### U-WAVE fit Bluetooth, Buzzer Type

Wireless Transmitter for  
Micrometer/Indicator  
Art No. 264-627

Promo price: **129.00 €\***  
Suggested retail price: ~~185.00 €\*~~

Promotion!

Mitutoyo


MiCAT  
the standard in world  
metrology software  
MeasurLink

### USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available  
Online)

Art No. 06AGR543

Promo price: **268.00 €\***  
Suggested retail price: ~~340.00 €\*~~

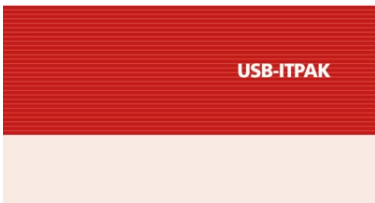

USB-ITPAK

Standard accessories:

## Micrometer Setting Standard



Length: 25mm  
Art No. 167-101  
Suggested retail price: 33.00 €\*  

---

## Spare parts

### Consumable spares:

---



## Battery SR44 1,5 V

Art No. 938882  
Suggested retail price: 7.00 €\*  

---