


Digital Sheet Metal Micrometer

Item number: 389-714

Images

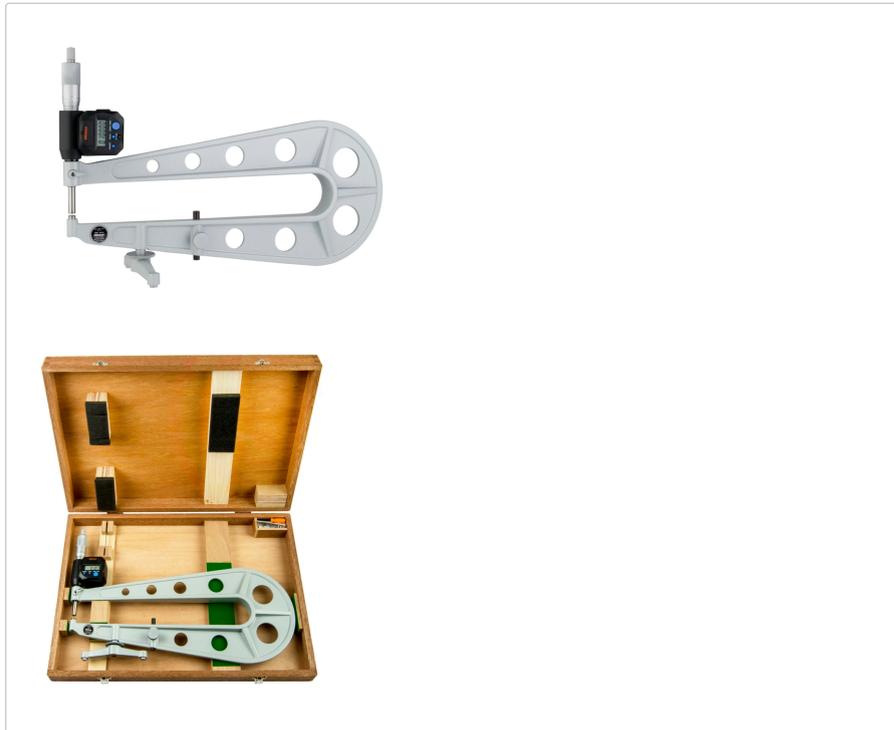

Description

A Mitutoyo waterproof digital micrometer suitable for use in the presence of coolant or cutting oil. The extra-deep frame (305mm / 12") enables measurement of sheet metal thickness farther from the edge of a sheet than is possible with a standard deep-frame micrometer. A ratchet stop guarantees repeatable measurement. Digimatic data output.

Features

Digital/Analog:	Digital
Inch-Metric:	Inch/Metric
Range:	0 - 1 "
Digital step:	0.00005"/0.001 mm
Max. Permissible Error J MPE:	±0.00025"
Delivered:	Including box, spanner, 2 SR44 batteries
Flatness:	0.00004"
Parallelism:	0.00012"
Display:	LCD, character height 7.5 mm
Measuring face:	Carbide-tipped, micro-lap finish
Anvil / Spindle:	Type A, flat/flat
Measuring spindle:	With spindle lock, throat depth ≤ 150 mm : ø 6,35 mm throat depth =300 mm : ø 8 mm, spindle pitch 0,5 mm

Scale:	Thimble and sleeve satin chrome finish, ø21 mm
Data output:	Yes
Measuring force:	10 - 14 N
Power supply:	2 batteries SR-44
Battery life:	Approx. 2.4 years, Approx. 1.8 years (389-514)
ORIGIN:	Yes
ABS / INC (INC ZERO):	Yes
Auto Power OFF after 20 min. non use:	Yes
Low voltage alarm:	Yes
Function lock:	Yes
HOLD:	Yes
2 x PRESET:	Yes
Mass:	2750 g

Accessories

Optional accessories:



Connection Cable C for U-WAVE
 Straight, with Data Button
 Art No. 02AZD790C
Promo price: 72.00 €*
 Suggested retail price: ~~105.00 €*~~



USB Input Tool Direct (Digimatic to USB)
 2m Cable, Digimatic/Digimatic 2, Straight, with Data Button
 Art No. 06AFM380C
Promo price: 98.00 €*
 Suggested retail price: ~~124.00 €*~~



Digimatic Cable, Straight, Data Button,

1 m
Art No. 959149
Suggested retail price: 48.00 €*



Digimatic Cable, Straight, Data Button

2 m
Art No. 959150
Suggested retail price: 57.00 €*



Digimatic Cable with Data Button

1 m, Flat L-Shape Left Type
Art No. 04AZB512
Suggested retail price: 95.00 €*



Digimatic Cable, Straight, Data Button

2 m, Flat L-Shape Left Type
Art No. 04AZB513
Suggested retail price: 106.00 €*

Promotion!



U-WAVE-T, IP67 Type

Wireless Transmitter
Art No. 02AZD730G
Promo price: **129.00 €***
Suggested retail price: ~~187.00 €*~~

Promotion!



U-WAVE-T, Buzzer Type

Wireless Transmitter

Art No. 02AZD880G

Promo price: **129.00 €***

Suggested retail price: ~~187.00 €*~~

Promotion!

Mitutoyo

MiCAT

the standard in world
metrology software
MeasurLink

USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available
Online)

Art No. 06AGR543

Promo price: **268.00 €***

Suggested retail price: ~~340.00 €*~~



Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 7.00 €*