

## Digital Tube Microm. Sph. Anvil/Spindle

Item number: 395-274-30

### Images



Dust- and  
Water-  
Protected

www.tuv.com  
ID 0000040191



### Description


This Digimatic Tube Micrometer allows you to measure curved surfaces such as the wall thickness of tubes, bearings and rings.

### Features


<b>Digital/Analog:</b>	Digital
<b>Inch-Metric:</b>	Metric
<b>Range:</b>	75 - 100 mm
<b>Digital step:</b>	0,001 mm
<b>Max. Permissible Error J MPE:</b>	±3 µm
<b>Delivered:</b>	Including box, spanner, setting standard, 1 SR44 battery
<b>Display:</b>	LCD, character height 7.5 mm
<b>Measuring face:</b>	Carbide-tipped, micro-lap finish
<b>Anvil / Spindle:</b>	Type B, spherical anvil and spindle SR=4 mm
<b>Measuring spindle:</b>	With spindle lock, ø6,35 mm, spindle pitch 0,5 mm

<b>Scale:</b>	Thimble and sleeve satin chrome finish, ø18 mm
<b>Data output:</b>	Yes
<b>Measuring force:</b>	5 - 10 N
<b>Power supply:</b>	1 battery SR-44
<b>Battery life:</b>	Approx. 2.4 years
<b>ORIGIN:</b>	Yes
<b>ABS / INC (INC ZERO):</b>	Yes
<b>Auto Power OFF after 20 min. non use:</b>	Yes
<b>Low voltage alarm:</b>	Yes
<b>Function lock:</b>	Yes
<b>HOLD:</b>	Yes
<b>Mass:</b>	625 g

**Dimensions**

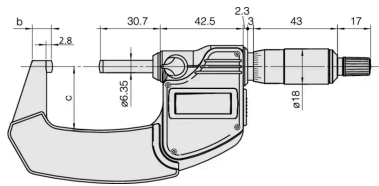

**D:** 20 mm  
**b:** 14 mm  
**c:** 60 mm

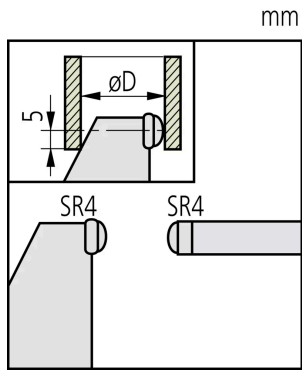

**D:** 20 mm  
**b:** 14 mm  
**c:** 60 mm

**Accessories**

Optional accessories:



**Micrometer Stand, Adjustable Angle Type**

for Micrometer 0-100mm/0-4"  
Art No. 156-101-10

Promo price: **56.00 €\***

Suggested retail price: ~~70.00 €\*~~

Promotion!



### Connection Unit for IP Caliper, Micrometer

with Data Button for U-WAVE fit, U-WAVE fit Bluetooth

Art No. 02AZF310

Promo price: **76.00 €\***

Suggested retail price: ~~110.00 €\*~~

Promotion!



### USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, with Data Button IP Micrometer Type

Art No. 06AFM380B

Promo price: **111.00 €\***

Suggested retail price: ~~141.00 €\*~~

### Digimatic Cable with Data Button IP Type



1 m, Micrometer Type

Art No. 05CZA662

Suggested retail price: 105.00 €\*

### Digimatic Cable with Data Button IP Type



2 m, Micrometer Type

Art No. 05CZA663

Suggested retail price: 107.00 €\*

Promotion!



### U-WAVE fit, IP67 Type

Wireless Transmitter for Micrometer/Indicator

Art No. 264-622

Promo price: **129.00 €\***

Suggested retail price: ~~185.00 €\*~~

Promotion!



### U-WAVE fit, Buzzer Type

Wireless Transmitter for  
Micrometer/Indicator  
Art No. 264-623

Promo price: **129.00 €\***  
Suggested retail price: ~~185.00 €\*~~

Promotion!



### U-WAVE fit Bluetooth, IP67 Type

Wireless Transmitter for  
Micrometer/Indicator  
Art No. 264-626

Promo price: **129.00 €\***  
Suggested retail price: ~~185.00 €\*~~

Promotion!



### U-WAVE fit Bluetooth, Buzzer Type

Wireless Transmitter for  
Micrometer/Indicator  
Art No. 264-627

Promo price: **129.00 €\***  
Suggested retail price: ~~185.00 €\*~~

Promotion!

Mitutoyo

**MiCAT**  
the standard in world  
metrology software  
**measurLink**

### USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available  
Online)

Art No. 06AGR543

Promo price: **268.00 €\***  
Suggested retail price: ~~340.00 €\*~~



Standard accessories:

### Micrometer Setting Standard

Length: 75mm  
Art No. 167-103  
Suggested retail price: 37.00 €\*



**Spare parts**

Consumable spares:

---



**Battery SR44 1,5 V**

Art No. 938882

Suggested retail price: 7.00 €\*  

---