

Digital Tube Micrometer, Spherical Anvil

Item number: 395-351-30

Images



Dust- and
Water-
Protected

www.tuv.com
ID 0000040191



Description


This Digimatic Tube Micrometer allows you to measure curved surfaces such as the wall thickness of tubes, bearings and rings.

Features

| | |
|--|--|
| Digital/Analog: | Digital |
| Inch-Metric: | Inch/Metric |
| Range: | 0 - 1 " |
| Digital step: | 0.00005"/0.001 mm |
| Max. Permissible Error J MPE: | ±0.0001" |
| Delivered: | Including box, spanner, 1 SR44 battery |
| Flatness: | 0.000012" |
| Display: | LCD, character height 7.5 mm |
| Measuring face: | Carbide-tipped, micro-lap finish |

| | |
|--|--|
| Anvil / Spindle: | Type A, spherical anvil SR=4 mm/flat spindle |
| Measuring spindle: | With spindle lock, $\varnothing 6,35$ mm, spindle pitch 0,5 mm |
| Scale: | Thimble and sleeve satin chrome finish, $\varnothing 18$ mm |
| Data output: | Yes |
| Measuring force: | 5 - 10 N |
| Power supply: | 1 battery SR-44 |
| Battery life: | Approx. 2.4 years |
| ORIGIN: | Yes |
| ABS / INC (INC ZERO): | Yes |
| Auto Power OFF after 20 min. non use: | Yes |
| Low voltage alarm: | Yes |
| Function lock: | Yes |
| HOLD: | Yes |
| Mass: | 270 g |

Dimensions

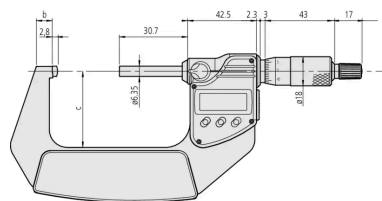

D: 15 mm

b: 9 mm

c: 25 mm

Accessories

Optional accessories:



Micrometer Stand, 45° Angle Type

for Micrometer 0-50mm/0-2"

Art No. 156-105-10

Suggested retail price: 58.00 €*

Promotion!



Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"

Art No. 156-101-10

Promo price: 56.00 €*

Suggested retail price: 70.00 €*

Promotion!



Connection Unit for IP Caliper, Micrometer

with Data Button for U-WAVE fit, U-WAVE fit Bluetooth

Art No. 02AZF310

Promo price: **76.00 €***

Suggested retail price: ~~110.00 €*~~

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, with Data Button IP Micrometer Type

Art No. 06AFM380B

Promo price: **111.00 €***

Suggested retail price: ~~141.00 €*~~

Digimatic Cable with Data Button IP Type



1 m, Micrometer Type

Art No. 05CZA662

Suggested retail price: 105.00 €*

Digimatic Cable with Data Button IP Type



2 m, Micrometer Type

Art No. 05CZA663

Suggested retail price: 107.00 €*

Promotion!



U-WAVE fit, IP67 Type

Wireless Transmitter for Micrometer/Indicator

Art No. 264-622

Promo price: **129.00 €***

Suggested retail price: ~~185.00 €*~~

Promotion!



U-WAVE fit, Buzzer Type

Wireless Transmitter for
Micrometer/Indicator

Art No. 264-623

Promo price: **129.00 €***

Suggested retail price: ~~185.00 €*~~

Promotion!



U-WAVE fit Bluetooth, IP67 Type

Wireless Transmitter for
Micrometer/Indicator

Art No. 264-626

Promo price: **129.00 €***

Suggested retail price: ~~185.00 €*~~

Promotion!



U-WAVE fit Bluetooth, Buzzer Type

Wireless Transmitter for
Micrometer/Indicator

Art No. 264-627

Promo price: **129.00 €***

Suggested retail price: ~~185.00 €*~~

Promotion!

Mitutoyo

MiCAT

the standard in world
metrology software
MeasurLink


USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available
Online)

Art No. 06AGR543

Promo price: **268.00 €***

Suggested retail price: ~~340.00 €*~~

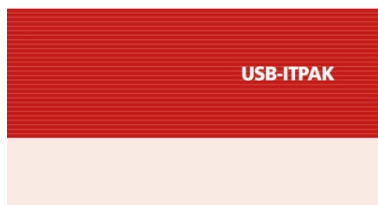

Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 7.00 €*
