

Digital Tube Microm. Sph. Anvil/Spindle

Item number: 395-372-30

Images



Dust- and Water-Protected

www.tuv.com
ID 0000040191



Description

This Digimatic Tube Micrometer allows you to measure curved surfaces such as the wall thickness of tubes, bearings and rings.

Features

Digital/Analog:	Digital
Inch-Metric:	Inch/Metric
Range:	1 - 2 "
Digital step:	0.00005"/0.001 mm
Max. Permissible Error J MPE:	±0.0001"
Delivered:	Including box, spanner, setting standard, 1 SR44 battery
Flatness:	0.000012"

Display:	LCD, character height 7.5 mm
Measuring face:	Carbide-tipped, micro-lap finish
Anvil / Spindle:	Type B, spherical anvil and spindle SR=4 mm
Measuring spindle:	With spindle lock, $\varnothing 6,35$ mm, spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish, $\varnothing 18$ mm
Data output:	Yes
Measuring force:	5 - 10 N
Power supply:	1 battery SR-44
Battery life:	Approx. 2.4 years
ORIGIN:	Yes
ABS / INC (INC ZERO):	Yes
Auto Power OFF after 20 min. non use:	Yes
Low voltage alarm:	Yes
Function lock:	Yes
HOLD:	Yes
Mass:	330 g

Dimensions

Technical drawing showing dimensions and cross-sections of the measuring tool. The main drawing includes dimensions: 2.8, 30.7, 42.5, 2.3, 43, 17, $\varnothing 6,35$, and $\varnothing 18$. Dimensions are labeled as **b**, **c**, and **D**.

D: 15 mm
b: 9.8 mm
c: 32 mm

mm

D: 15 mm
b: 9.8 mm
c: 32 mm

SR4 SR4

Accessories

Optional accessories:



Micrometer Stand, 45° Angle Type

for Micrometer 0-50mm/0-2"
Art No. 156-105-10
Suggested retail price: 58.00 €*
(Price is crossed out in the original image)

Promotion!



Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"
Art No. 156-101-10
Promo price: **56.00 €*
~~70.00 €*
(Price is crossed out in the original image)~~**

Promotion!



Connection Unit for IP Caliper, Micrometer

with Data Button for U-WAVE fit, U-WAVE fit Bluetooth
Art No. 02AZF310
Promo price: **76.00 €*
~~110.00 €*
(Price is crossed out in the original image)~~**

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, with Data Button IP Micrometer Type
Art No. 06AFM380B
Promo price: **111.00 €*
~~141.00 €*
(Price is crossed out in the original image)~~**



Digimatic Cable with Data Button IP Type

1 m, Micrometer Type
Art No. 05CZA662
Suggested retail price: 105.00 €*
(Price is crossed out in the original image)



Digimatic Cable with Data Button IP Type

2 m, Micrometer Type
Art No. 05CZA663
Suggested retail price: 107.00 €*
Suggested retail price: 107.00 €*
Suggested retail price: 107.00 €*

Promotion!



U-WAVE fit, IP67 Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-622
Promo price: **129.00 €***
Suggested retail price: 185.00 €*
Suggested retail price: 185.00 €*

Promotion!



U-WAVE fit, Buzzer Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-623
Promo price: **129.00 €***
Suggested retail price: 185.00 €*
Suggested retail price: 185.00 €*

Promotion!



U-WAVE fit Bluetooth, IP67 Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-626
Promo price: **129.00 €***
Suggested retail price: 185.00 €*
Suggested retail price: 185.00 €*

Promotion!



U-WAVE fit Bluetooth, Buzzer Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-627
Promo price: **129.00 €***
Suggested retail price: 185.00 €*
Suggested retail price: 185.00 €*

Promotion!

Mitutoyo

MiCAT

the standard in world
metrology software
MeasurLink®

USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available
Online)


Art No. 06AGR543

Promo price: 268.00 €*

~~Suggested retail price: 340.00 €*~~

USB-ITPAK

Standard accessories:

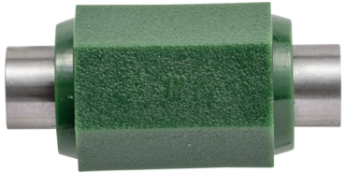

Micrometer Setting Standard

Length: 1"

Art No. 167-141

Suggested retail price: 33.00 €*

Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 7.00 €*