


Digital Microm., Non Rotating Spindle

Item number: 406-352-30

Images

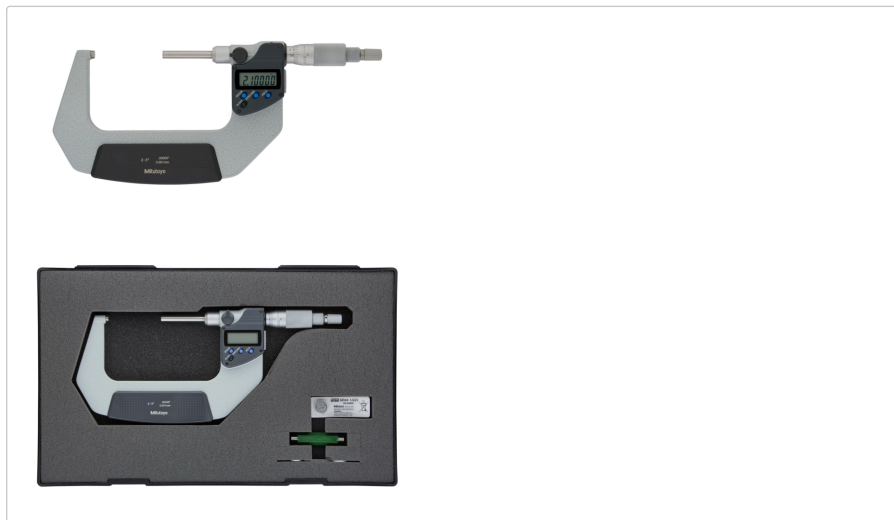

Description

This Micrometer features a non-rotating spindle, and offers the following benefits:

- Sliding spindle, not rotating.
- Ratchet stop.
- Data output.

Features

Digital/Analog:	Digital
Delivered:	Including box, setting standard, 1 battery, key
Inch-Metric:	Inch/Metric
Range:	2 - 3 "
Digital step:	0.00005"/0.001 mm
Max. Permissible Error J MPE:	±0.00015"
Flatness:	0.000012"
Parallelism:	0.00012"
Data output:	Yes
Display:	LCD, character height 7.5 mm
Measuring face:	Carbide-tipped, micro-lap finish
Measuring spindle:	With spindle lock, \varnothing 6.35 mm, spindle pitch 0.5 mm
Scale:	Thimble and sleeve satin chrome finish, \varnothing 18 mm
Measuring force:	3 - 8 N
Power supply:	1 battery SR-44
Battery life:	Approx. 2.4 years
ORIGIN:	Yes

ABS / INC (INC ZERO):	Yes
Auto Power OFF after 20 min. non use:	Yes
Low voltage alarm:	Yes
Function lock:	Yes
HOLD:	Yes
Mass:	625 g

Accessories

Optional accessories:

Promotion!



Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"
Art No. 156-101-10

Promo price: **55.90 €***
Suggested retail price: ~~70.00 €*~~

Promotion!



Connection Unit for IP Caliper, Micrometer

with Data Button for U-WAVE fit, U-WAVE fit Bluetooth
Art No. 02AZF310

Promo price: **74.90 €***
Suggested retail price: ~~110.00 €*~~

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, with Data Button IP Micrometer Type
Art No. 06AFM380B

Promo price: **109.00 €***
Suggested retail price: ~~141.00 €*~~



Digimatic Cable with Data Button IP Type

1m, Micrometer Type
Art No. 05CZA662
Suggested retail price: 105.00 €*



Digimatic Cable with Data Button IP Type

2m, Micrometer Type
Art No. 05CZA663
Suggested retail price: 107.00 €*
Suggested retail price: 107.00 €*
Suggested retail price: 107.00 €*

Promotion!



U-WAVE fit, IP67 Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-622
Promo price: 129.00 €*
Suggested retail price: 185.00 €*

Promotion!



U-WAVE fit, Buzzer Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-623
Promo price: 129.00 €*
Suggested retail price: 185.00 €*

Promotion!



U-WAVE fit Bluetooth, IP67 Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-626
Promo price: 139.00 €*
Suggested retail price: 185.00 €*

Promotion!



U-WAVE fit Bluetooth, Buzzer Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-627
Promo price: 139.00 €*
Suggested retail price: 185.00 €*

Promotion!

Mitutoyo

MiCAT

the standard in world
metrology software
MeasurLink®

USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available
Online)

Art No. 06AGR543

Promo price: 259.00 €*

~~Suggested retail price: 340.00 €*~~

USB-ITPAK

Standard accessories:

Micrometer Setting Standard

Length: 2"

Art No. 167-142

Suggested retail price: 36.00 €*



Spare parts

Consumable spares:

Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 10.00 €*

