

Absolute Digital Blade Mic. QuickMike

Item number: 422-412-20

Images



Dust- and
Water-
Protected

www.tuv.com
ID 0000063013

ABSOLUTE®

IP65

Description

This ABSOLUTE Digimatic Blade Micrometer Quickmike is designed to help you measure hard-to-reach features. It offers the following benefits:


- Blade-shaped anvil and spindle for measuring the groove diameter of shafts, keyways and other hard-to reach features
- Non-rotating spindle
- Fast spindle feed of 10 mm/revolution

Features

Digital/Analog:	Digital
Inch-Metric:	Metric
Range:	25 - 55 mm
Digital step:	0,001 mm
Max. Permissible Error J MPE:	±3 µm
Delivered:	Including box, setting standard, 1 SR44 battery

Parallelism:	3 μ m
Display:	LCD, character height 10 mm
Measuring face:	Carbide-tipped or hardened steel spindle and anvil
Anvil / Spindle:	Type A, hardened steel t=0.75 mm
Measuring spindle:	\varnothing 6,35 mm, non-rotating, spindle feed 10 mm
Data output:	Yes
Measuring force:	5 - 12 N
Power supply:	1 battery SR-44
Battery life:	Approx. 5 years
ON/OFF:	Yes
ORIGIN:	Yes
ABS / INC (INC ZERO):	Yes
Low voltage alarm:	Yes
HOLD:	Yes
Mass:	490 g

Dimensions

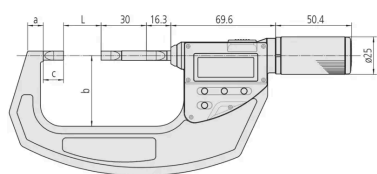


L: 25 mm

a: 10.3 mm

b: 47 mm

c: 13.5 mm

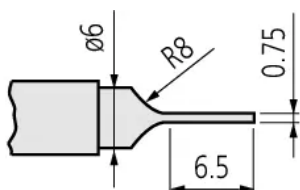


L: 25 mm

a: 10.3 mm

b: 47 mm

c: 13.5 mm

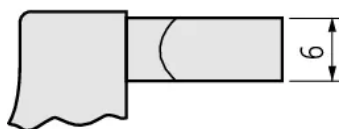

Accessories

Optional accessories:



Digimatic Cable with Data Button IP Type

1 m, Micrometer Type

Art No. 05CZA662

Suggested retail price: 105.00 €*

Promotion!

Mitutoyo

MiCAT

the standard in world
metrology software
MeasurLink®

USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available
Online)

Art No. 06AGR543

Promo price: 268.00 €*

~~Suggested retail price: 340.00 €*~~

USB-ITPAK

Standard accessories:



Micrometer Setting Standard

Length: 25mm

Art No. 167-101

Suggested retail price: 33.00 €*

Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 7.00 €*