

Digital 3-Point Internal Micrometer

Item number: 468-168

Images



Dust- and
Waterproof
IP65

www.tuv.com
ID 0000021605



Description

These are three-point internal micrometers that offer you the following benefits:


- Individual micrometer.
- Titanium-coated measuring pins give you excellent durability and impact resistance.
- They also have excellent resistance against water and dust (IP65 protection level), allowing you to use this product in machining situations that include splashing coolant fluid.
- Large LCD display with character height of 7,5 mm enables you to read measurements easily.

- Without setting rings or extensions.

Features

Model:	HTD-40R
Digital/Analog:	Digital
Inch-Metric:	Metric
Range:	30 - 40 mm
Digital step:	0,001 mm
Max. Permissible Error J MPE:	$\pm 3 \mu\text{m}$
Display:	LCD, character height 7.5 mm
Measuring face:	Titanium-coated hardened steel taper: tungsten carbide
Power supply:	1 battery SR-44
Battery life:	Approx. 1.2 years
ABS / INC (INC ZERO):	Yes
Auto Power OFF after 20 min. non use:	Yes
Low voltage alarm:	Yes
Function lock:	Yes
HOLD:	Yes
2 x PRESET:	Yes
Delivered:	Including box, hex wrench, spanner, screwdriver, 1 SR44 battery, certificate of inspection
Data output:	Yes
Mass:	480 g

Dimensions

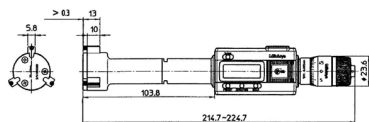

Accessories

Optional accessories:

Promotion!



Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"
Art No. 156-101-10

Promo price: 55.90 €*
~~Suggested retail price: 70.00 €*~~

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 10.00 €*
