

Digital 3-Point Internal Micrometer

Item number: 468-170

Images



Dust- and
Waterproof
IP65

www.tuv.com
ID 0000021605



Description

These are three-point internal micrometers that offer you the following benefits:


- Individual micrometer.
- Titanium-coated measuring pins give you excellent durability and impact resistance.
- They also have excellent resistance against water and dust (IP65 protection level), allowing you to use this product in machining situations that include splashing coolant fluid.
- Large LCD display with character height of 7,5 mm enables you to read measurements easily.

- Without setting rings or extensions.

Features

Model:	HTD-63R
Inch-Metric:	Metric
Digital/Analog:	Digital
Range:	50 - 63 mm
Digital step:	0,001 mm
Max. Permissible Error J MPE:	$\pm 3 \mu\text{m}$
Power supply:	1 battery SR-44
Battery life:	Approx. 1.2 years
Display:	LCD, character height 7.5 mm
Measuring face:	Titanium-coated hardened steel taper: tungsten carbide
ABS / INC (INC ZERO):	Yes
Auto Power OFF after 20 min. non use:	Yes
Low voltage alarm:	Yes
Function lock:	Yes
HOLD:	Yes
2 x PRESET:	Yes
Delivered:	Including box, hex wrench, spanner, screwdriver, 1 SR44 battery, certificate of inspection
Data output:	Yes
Mass:	620 g

Dimensions

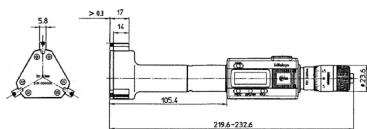

Accessories

Optional accessories:



Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"

Art No. 156-101-10

Promo price: 56.00 €*

Suggested retail price: 70.00 €*



Setting Ring 50mm

Steel

Art No. 177-146

Suggested retail price: 215.00 €*
~~215.00 €*
215.00 €*~~

Promotion!



Connection Cable B for U-WAVE

with Data Button for IP Micrometer Type

Art No. 02AZD790B

Promo price: **76.00 €*
~~110.00 €*
110.00 €*~~**

Suggested retail price: 110.00 €*
~~110.00 €*
110.00 €*~~

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, with Data Button IP Micrometer Type

Art No. 06AFM380B

Art No. 06AFM380B

Promo price: **111.00 €*
~~141.00 €*
141.00 €*~~**

Suggested retail price: 141.00 €*
~~141.00 €*
141.00 €*~~



Digimatic Cable with Data Button IP Type

1 m, Micrometer Type

Art No. 05CZA662

Suggested retail price: 105.00 €*
~~105.00 €*
105.00 €*~~



Digimatic Cable with Data Button IP Type

2 m, Micrometer Type

Art No. 05CZA663

Suggested retail price: 107.00 €*
~~107.00 €*
107.00 €*~~

Holder for Micrometer Stand

for Series 468
Art No. 04AZB157
Suggested retail price: 62.00 €*
~~62.00 €~~



Holtest, Borematic Extension 150mm

for 50-300mm Measuring Range
Art No. 952623
Suggested retail price: 216.00 €*
~~216.00 €~~



Promotion!

U-WAVE-T, IP67 Type

Wireless Transmitter
Art No. 02AZD730G
Promo price: 129.00 €*
Suggested retail price: 187.00 €*
~~187.00 €~~



Promotion!

U-WAVE-T, Buzzer Type

Wireless Transmitter
Art No. 02AZD880G
Promo price: 129.00 €*
Suggested retail price: 187.00 €*
~~187.00 €~~



Promotion!

Mitutoyo

MiCAT
the standard in world
metrology software
MeasurLink

USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available Online)
Art No. 06AGR543
Promo price: 268.00 €*
Suggested retail price: 340.00 €*
~~340.00 €~~

USB-ITPAK

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 7.00 €*
