

Digital 3-Point Internal Micrometer

Item number: 468-179

Images



Dust- and
Waterproof
IP65

www.tuv.com
ID 0000021605



Description

These are three-point internal micrometers that offer you the following benefits:


- Individual micrometer.
- Titanium-coated measuring pins give you excellent durability and impact resistance.
- They also have excellent resistance against water and dust (IP65 protection level), allowing you to use this product in machining situations that include splashing coolant fluid.
- Large LCD display with character height of 7,5 mm enables you to read measurements easily.

- Without setting rings or extensions.

Features

Model:	HTD-250R
Digital/Analog:	Digital
Inch-Metric:	Metric
Range:	225 - 250 mm
Digital step:	0,001 mm
Max. Permissible Error J MPE:	±6 µm
Display:	LCD, character height 7.5 mm
Measuring face:	Titanium-coated hardened steel taper: tungsten carbide
Power supply:	1 battery SR-44
Battery life:	Approx. 1.2 years
ABS / INC (INC ZERO):	Yes
Auto Power OFF after 20 min. non use:	Yes
Low voltage alarm:	Yes
Function lock:	Yes
HOLD:	Yes
2 x PRESET:	Yes
Delivered:	Including box, hex wrench, spanner, screwdriver, 1 SR44 battery, certificate of inspection
Data output:	Yes
Mass:	1390 g

Dimensions

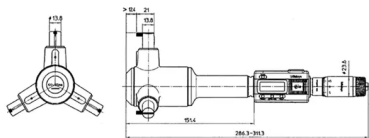

Accessories

Optional accessories:



Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"

Art No. 156-101-10

Promo price: **55.90 €***

~~Suggested retail price: 70.00 €*~~



Setting Ring 225mm

Steel
Art No. 177-306
Suggested retail price: 2,177.00 €*
Suggested retail price: 2,177.00 €*
Suggested retail price: 2,177.00 €*

Promotion!



Connection Cable B for U-WAVE

with Data Button for IP Micrometer Type
Art No. 02AZD790B

Promo price: **72.90 €*
Suggested retail price: 110.00 €***

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, with Data Button IP Micrometer Type
Art No. 06AFM380B

Promo price: **109.00 €*
Suggested retail price: 141.00 €***



Digimatic Cable with Data Button IP Type

1m, Micrometer Type
Art No. 05CZA662
Suggested retail price: 105.00 €*
Suggested retail price: 105.00 €*



Digimatic Cable with Data Button IP Type

2m, Micrometer Type
Art No. 05CZA663
Suggested retail price: 107.00 €*
Suggested retail price: 107.00 €*

Holder for Micrometer Stand



for Series 468
Art No. 04AZB157
Suggested retail price: 62.00 €*
~~62.00 €*~~

Holtest, Borematic Extension 150mm



for 50-300mm Measuring Range
Art No. 952623
Suggested retail price: 222.00 €*
~~222.00 €*~~

Promotion!



U-WAVE-T, IP67 Type

Wireless Transmitter
Art No. 02AZD730G
Promo price: **129.00 €***
Suggested retail price: ~~187.00 €*~~

Promotion!



U-WAVE-T, Buzzer Type

Wireless Transmitter
Art No. 02AZD880G
Promo price: **129.00 €***
Suggested retail price: ~~187.00 €*~~

Promotion!

Mitutoyo

MiCAT
the standard in world
metrology software
MeasurLink

USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available
Online)
Art No. 06AGR543
Promo price: **259.00 €***
Suggested retail price: ~~340.00 €*~~

USB-ITPAK

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 10.00 €*
