

Digital 3-Point Internal Micrometer

Item number: 468-181

Images



Dust- and
Waterproof
IP65

www.tuv.com
ID 0000021605



Description

These are three-point internal micrometers that offer you the following benefits:


- Individual micrometer.
- Titanium-coated measuring pins give you excellent durability and impact resistance.
- They also have excellent resistance against water and dust (IP65 protection level), allowing you to use this product in machining situations that include splashing coolant fluid.
- Large LCD display with character height of 7,5 mm enables you to read measurements easily.

- Without setting rings or extensions.

Features

Model:	HTD-300R
Inch-Metric:	Metric
Digital/Analog:	Digital
Range:	275 - 300 mm
Digital step:	0,001 mm
Max. Permissible Error J MPE:	±6 µm
Power supply:	1 battery SR-44
Battery life:	Approx. 1.2 years
Display:	LCD, character height 7.5 mm
Measuring face:	Titanium-coated hardened steel taper: tungsten carbide
ABS / INC (INC ZERO):	Yes
Auto Power OFF after 20 min. non use:	Yes
Low voltage alarm:	Yes
Function lock:	Yes
HOLD:	Yes
2 x PRESET:	Yes
Delivered:	Including box, hex wrench, spanner, screwdriver, 1 SR44 battery, certificate of inspection
Data output:	Yes
Mass:	1570 g

Dimensions

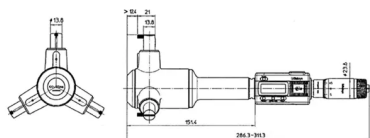

Accessories

Optional accessories:



Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"
Art No. 156-101-10

Promo price: **56.00 €***

Suggested retail price: ~~70.00 €*~~



Setting Ring 275mm

Steel

Art No. 177-310

Suggested retail price: 2,723.00 €*
~~2,723.00 €*
2,723.00 €*~~

Promotion!



Connection Cable B for U-WAVE

with Data Button for IP Micrometer Type

Art No. 02AZD790B

Promo price: **76.00 €*
~~110.00 €*
110.00 €*~~**

Suggested retail price: 110.00 €*
~~110.00 €*
110.00 €*~~

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, with Data Button IP Micrometer Type

Art No. 06AFM380B

Promo price: **111.00 €*
~~141.00 €*
141.00 €*~~**

Suggested retail price: 141.00 €*
~~141.00 €*
141.00 €*~~



Digimatic Cable with Data Button IP Type

1 m, Micrometer Type

Art No. 05CZA662

Suggested retail price: 105.00 €*
~~105.00 €*
105.00 €*~~



Digimatic Cable with Data Button IP Type

2 m, Micrometer Type

Art No. 05CZA663

Suggested retail price: 107.00 €*
~~107.00 €*
107.00 €*~~

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 7.00 €*
