


## Digital ABS AOS Caliper, ID/OD

### Carb. Ja.

Item number: 500-155-30

#### Images

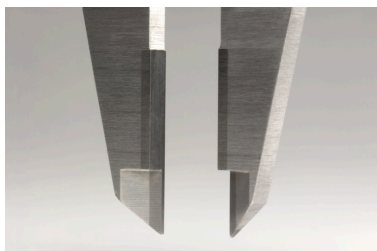

# ABSOLUTE®



#### Description

These Digimatic calipers have carbide-tipped jaws and allow you to take reliable measurements and offer you the following benefits:


- Thanks to the adoption of the electromagnetic induction type ABS encoder, this caliper can be used without concern for contamination on the scale face during measurement. Detection signal is not affected by dirt (water, oil, etc.) on surface of a scale.
- The slider provides smooth, stable and comfortable operation.
- Character height: 9 mm (alleviation of fatigue with the high-contrast LCD)
- The ABS (ABSOLUTE) scale requires no origin setting after power-on and also has no limit to response speed.
- Extraordinary battery life.

#### Features

<b>Model:</b>	CD-15AXWW
<b>Delivered:</b>	Including box, SR44 battery, certificate of inspection
<b>Depth bar:</b>	flat

<b>Thumb roller:</b>	Yes
<b>Data output:</b>	Yes
<b>Max. Permissible Error E MPE:</b>	±0,02 mm
<b>Max. Permissible Error S MPE:</b>	±0,04 mm
<b>Digital step:</b>	0,01 mm
<b>Max. response speed:</b>	Unlimited
<b>ORIGIN (ABS-Zero):</b>	Yes
<b>ON/OFF:</b>	Yes
<b>ABS / INC (INC ZERO):</b>	Yes
<b>Low voltage alarm:</b>	Yes
<b>Battery life:</b>	Approx. 5 years under normal use
<b>Mass:</b>	168 g

## Dimensions

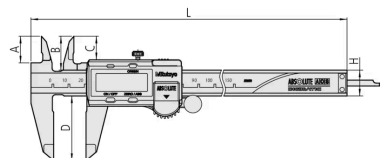

**L:** 233 mm

**A:** 16.5 mm

**B:** 21 mm

**C:** 14.5 mm

**D:** 40 mm

**H:** 16 mm

## Accessories

### Optional accessories:

Mitutoyo

**MiCAT**  
the standard in world  
metrology software  
**measurLink**

### USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available Online)

Art No. 06AGR543

Suggested retail price: **340.00 €\***

USB-ITPAK



### Digimatic Cable, Straight, Data Button,

1m

Art No. 959149

Suggested retail price: **48.00 €\***



### **Digimatic Cable, Straight, Data Button**

2m  
Art No. 959150  
Suggested retail price: 57.00 €\*  

---



### **USB Input Tool Direct (Digimatic to USB)**

2m Cable, Digimatic/Digimatic 2, Straight,  
with Data Button  
Art No. 06AFM380C  
Suggested retail price: 124.00 €\*  

---



### **U-WAVE fit, IP67 Type**

Wireless Transmitter for Caliper  
Art No. 264-620  
Suggested retail price: 185.00 €\*  

---



### **U-WAVE fit, Buzzer Type**

Wireless Transmitter for Caliper  
Art No. 264-621  
Suggested retail price: 185.00 €\*  

---



### **U-WAVE fit Bluetooth, IP67 Type**

Wireless Transmitter for Caliper  
Art No. 264-624  
Suggested retail price: 185.00 €\*  

---



### U-WAVE fit Bluetooth, Buzzer Type

Wireless Transmitter for Caliper  
Art No. 264-625  
Suggested retail price: 185.00 €\*  

---



### Connection Unit for Standard Caliper

with Data Button for U-WAVE fit, U-WAVE fit Bluetooth  
Art No. 02AZF300  
Suggested retail price: 105.00 €\*  

---



### Data Hold Unit

for Digital Caliper  
Art No. 959143  
Suggested retail price: 39.50 €\*  

 
---



### Depth Base Attachment for Caliper

75mm width for 100, 150, 200mm Range  
Art No. 050083-10  
Suggested retail price: 60.00 €\*  

---



### Depth Base Attachment for Caliper

100mm width for 100, 150, 200mm Range  
Art No. 050084-10  
Suggested retail price: 67.00 €\*  

---

Consumable spares:

---



**Battery SR44 1,5 V**

Art No. 938882

Suggested retail price: 7.00 €\*  

---