

## Digital ABS AOS Caliper, OD Carb. Jaws

Item number: 500-167-30

### Images



# ABSOLUTE®



### Description

These Digimatic calipers have carbide-tipped jaws and allow you to take reliable measurements and offer you the following benefits:


- Thanks to the adoption of the electromagnetic induction type ABS encoder, this caliper can be used without concern for contamination on the scale face during measurement. Detection signal is not affected by dirt (water, oil, etc.) on surface of a scale.
- The slider provides smooth, stable and comfortable operation.
- Character height: 9 mm (alleviation of fatigue with the high-contrast LCD)
- The ABS (ABSOLUTE) scale requires no origin setting after power-on and also has no limit to response speed.
- Extraordinary battery life.

### Features

|                                      |  |
|--------------------------------------|--|
| <b>Model:</b>                        | CD-12"AXW  |
| <b>Range:</b>                        | 0 - 12 "   |
| <b>Delivered:</b>                    | Including box, SR44 battery, certificate of inspection |
| <b>Depth bar:</b>                    | flat   |
| <b>Thumb roller:</b>                 | Yes  |
| <b>Data output:</b>                  | Yes  |
| <b>Max. Permissible Error E MPE:</b> | ±0,0015"   |
| <b>Max. Permissible Error S MPE:</b> | ±0,0025"   |

|                              |                                  |
|------------------------------|----------------------------------|
| <b>Digital step:</b>         | 0.0005"/0.01 mm                  |
| <b>Max. response speed:</b>  | Unlimited                        |
| <b>ORIGIN (ABS-Zero):</b>    | Yes                              |
| <b>ON/OFF:</b>               | Yes                              |
| <b>ABS / INC (INC ZERO):</b> | Yes                              |
| <b>Low voltage alarm:</b>    | Yes                              |
| <b>Battery life:</b>         | Approx. 5 years under normal use |
| <b>Mass:</b>                 | 350 g                            |

## Dimensions

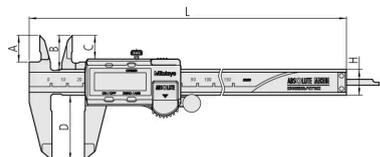

**L:** 404 mm

**A:** 22 mm

**B:** 27.5 mm

**C:** 19.8 mm

**D:** 64 mm

**H:** 20 mm

## Accessories

### Optional accessories:

Mitutoyo

MICAT

the standard in world  
metrology software  
measurLink

### USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available  
Online)

Art No. 06AGR543

Suggested retail price: 340.00 €\*

USB-ITPAK

### Standard accessories:



### Connection Unit for Standard Caliper

with Data Button for U-WAVE fit, U-WAVE fit  
Bluetooth

Art No. 02AZF300

Suggested retail price: 105.00 €\*



### U-WAVE fit, IP67 Type

Wireless Transmitter for Caliper  
Art No. 264-620  
Suggested retail price: 185.00 €\*



### U-WAVE fit, Buzzer Type

Wireless Transmitter for Caliper  
Art No. 264-621  
Suggested retail price: 185.00 €\*



### USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, Straight,  
with Data Button  
Art No. 06AFM380C  
Suggested retail price: 124.00 €\*



### Digimatic Cable, Straight, Data Button,

1m  
Art No. 959149  
Suggested retail price: 48.00 €\*



### Digimatic Cable, Straight, Data Button

2m  
Art No. 959150  
Suggested retail price: 57.00 €\*

## Depth Base Attachment for Caliper



125mm width for 300mm Range  
Art No. 050085-10  
Suggested retail price: 74.00 €\*  

---

## Data Hold Unit



for Digital Caliper  
Art No. 959143  
Suggested retail price: 39.50 €\*  

---

## Spare parts

Consumable spares:

---



## Battery SR44 1,5 V

Art No. 938882  
Suggested retail price: 7.00 €\*  

---

button battery

Art No. ED002

Price on application

