

Digital ABS AOS Caliper

Item number: 500-193-30

Images



Description

This digimatic caliper allows you to take reliable measurements and offers you the following benefits:


- AOS (Advanced Onsite Sensor) induction type encoder used in top-of-the-line ABS coolant-proof calipers
- Thanks to the adoption of the electromagnetic induction type ABS encoder, this caliper can be used without concern for contamination on the scale face during measurement. Detection signal is not affected by dirt (water, oil, etc.) on surface of a scale.
- ABS (ABSOLUTE) scale requires no origin setting after power-on and has no limit to response speed.

Features

Model:	CD-12"ASX
Range:	0 - 12 "
Delivered:	Including box, SR44 battery, certificate of inspection
Depth bar:	flat
Thumb roller:	Yes
Data output:	No
Max. Permissible Error E MPE:	$\pm 0,0015''$
Max. Permissible Error S MPE:	$\pm 0,0025''$
Digital step:	0.0005"/0.01 mm
Max. response speed:	Unlimited
Display:	LCD, character height 9 mm (150, 200 mm) 11 mm (300 mm)

ORIGIN (ABS-Zero):	Yes
ON/OFF:	Yes
ABS / INC (INC ZERO):	Yes
Low voltage alarm:	Yes
Battery life:	Approx. 5 years under normal use
Mass:	350 g

Dimensions

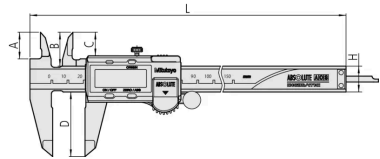

A: 22 mm

B: 27.5 mm

C: 19.8 mm

D: 64 mm

H: 20 mm

Accessories

Optional accessories:

 


Depth Base Attachment for Caliper

75mm width for 100, 150, 200mm Range

Art No. 050083-10

Suggested retail price: **60.00 €***



Depth Base Attachment for Caliper

100mm width for 100, 150, 200mm Range

Art No. 050084-10

Suggested retail price: **67.00 €***

Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 7.00 €*
*including VAT



button battery

Art No. ED002

Price on application