


## Digital ABS AOS Caliper

Item number: 500-202-30

### Images

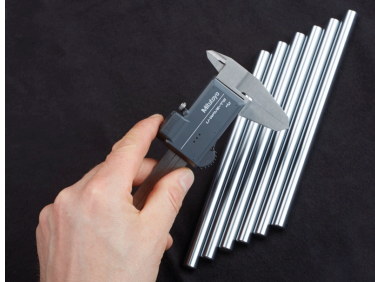

### Description

This digimatic caliper allows you to take reliable measurements and offers you the following benefits:


- AOS (Advanced Onsite Sensor) induction type encoder used in top-of-the-line ABS coolant-proof calipers
- Thanks to the adoption of the electromagnetic induction type ABS encoder, this caliper can be used without concern for contamination on the scale face during measurement. Detection signal is not affected by dirt (water, oil, etc.) on surface of a scale.
- ABS (ABSOLUTE) scale requires no origin setting after power-on and has no limit to response speed.

### Features

<b>Model:</b>	CD-6"DAX
<b>Delivered:</b>	Including box, SR44 battery, certificate of inspection
<b>Range:</b>	0 - 6 "
<b>Depth bar:</b>	flat
<b>Data output:</b>	Yes
<b>Max. Permissible Error E MPE:</b>	±0.001"
<b>Max. Permissible Error S MPE:</b>	±0.002"
<b>Digital step:</b>	0.0005"/0.01 mm
<b>Max. response speed:</b>	Unlimited
<b>Display:</b>	LCD, character height 9 mm (150, 200 mm) 11 mm (300 mm)

<b>ORIGIN (ABS-Zero):</b>	Yes
<b>ON/OFF:</b>	Yes
<b>ABS / INC (INC ZERO):</b>	Yes
<b>Low voltage alarm:</b>	Yes
<b>Battery life:</b>	Approx. 5 years under normal use
<b>Mass:</b>	168 g

## Dimensions

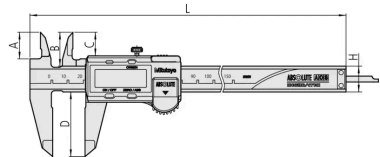

**A:** 16.5 mm

**B:** 21 mm

**C:** 14.5 mm

**D:** 40 mm

**H:** 16 mm

## Accessories

### Optional accessories:

**Promotion!**

**Mitutoyo**

**MiCAT**  
the standard in world metrology software  
**MeasurLink**

**USB-ITPAK**

**USB-ITPAK Vers. 3.0**  
USB Dongle + Manual (Software available Online)  
Art No. 06AGR543  
Promo price: **259.00 €\***  
Suggested retail price: ~~340.00 €\*~~



### Digimatic Cable, Straight, Data Button,

1m

Art No. 959149

Suggested retail price: 48.00 €\*



### Digimatic Cable, Straight, Data Button

2m

Art No. 959150

Suggested retail price: 57.00 €\*

Promotion!



### USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, Straight,  
with Data Button  
Art No. 06AFM380C

Promo price: **98.90 €\***

Suggested retail price: ~~124.00 €\*~~

Promotion!



### U-WAVE fit, IP67 Type

Wireless Transmitter for Caliper  
Art No. 264-620

Promo price: **129.00 €\***

Suggested retail price: ~~185.00 €\*~~

Promotion!



### U-WAVE fit, Buzzer Type

Wireless Transmitter for Caliper  
Art No. 264-621

Promo price: **129.00 €\***

Suggested retail price: ~~185.00 €\*~~

Promotion!



### U-WAVE fit Bluetooth, IP67 Type

Wireless Transmitter for Caliper  
Art No. 264-624

Promo price: **139.00 €\***

Suggested retail price: ~~185.00 €\*~~

Promotion!



### U-WAVE fit Bluetooth, Buzzer Type

Wireless Transmitter for Caliper  
Art No. 264-625

Promo price: **139.00 €\***

Suggested retail price: ~~185.00 €\*~~

Promotion!



## Connection Unit for Standard Caliper

with Data Button for U-WAVE fit, U-WAVE fit Bluetooth

Art No. 02AZF300

Promo price: **74.90 €\***

Suggested retail price: ~~105.00 €\*~~




## Data Hold Unit

for Digital Caliper

Art No. 959143

Suggested retail price: **36.00 €\***

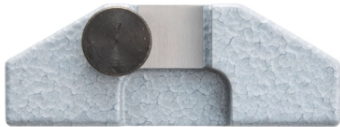


## Depth Base Attachment for Caliper

75mm width for 100, 150, 200mm Range

Art No. 050083-10

 Suggested retail price: **60.00 €\***



## Depth Base Attachment for Caliper

100mm width for 100, 150, 200mm Range

Art No. 050084-10

Suggested retail price: **67.00 €\***

## Spare parts

Consumable spares:



## Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 10.00 €\*  

---