


Digital ABS AOS Caliper

Item number: 500-204-30

Images

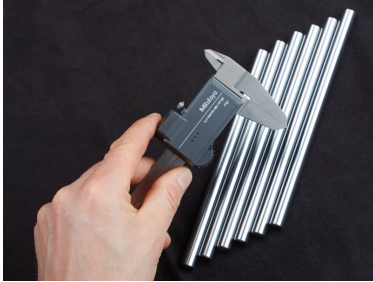

Description

This digimatic caliper allows you to take reliable measurements and offers you the following benefits:


- AOS (Advanced Onsite Sensor) induction type encoder used in top-of-the-line ABS coolant-proof calipers
- Thanks to the adoption of the electromagnetic induction type ABS encoder, this caliper can be used without concern for contamination on the scale face during measurement. Detection signal is not affected by dirt (water, oil, etc.) on surface of a scale.
- ABS (ABSOLUTE) scale requires no origin setting after power-on and has no limit to response speed.

Features

Model:	CD-8"DAX
Delivered:	Including box, SR44 battery, certificate of inspection
Range:	0 - 8 "
Depth bar:	flat
Data output:	Yes
Max. Permissible Error E MPE:	±0.001"
Max. Permissible Error S MPE:	±0.002"
Digital step:	0.0005"/0.01 mm
Max. response speed:	Unlimited

Display:	LCD, character height 9 mm (150, 200 mm) 11 mm (300 mm)
ORIGIN (ABS-Zero):	Yes
ON/OFF:	Yes
ABS / INC (INC ZERO):	Yes
Low voltage alarm:	Yes
Battery life:	Approx. 5 years under normal use
Mass:	194 g

Dimensions

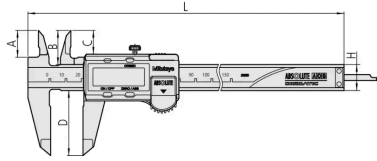

A: 20 mm

B: 24.5 mm

C: 18 mm

D: 50 mm

H: 16 mm

Accessories

Optional accessories:

Promotion!



Connection Unit for Standard Caliper

with Data Button for U-WAVE fit, U-WAVE fit
Bluetooth

Art No. 02AZF300

Promo price: 74.90 €*

~~Suggested retail price: 105.00 €*~~

Promotion!



U-WAVE fit Bluetooth, IP67 Type

Wireless Transmitter for Caliper

Art No. 264-624

Promo price: 139.00 €*

~~Suggested retail price: 185.00 €*~~

Promotion!



U-WAVE fit Bluetooth, Buzzer Type

Wireless Transmitter for Caliper

Art No. 264-625

Promo price: 139.00 €*

~~Suggested retail price: 185.00 €*~~

Promotion!



U-WAVE fit, IP67 Type

Wireless Transmitter for Caliper
Art No. 264-620

Promo price: **129.00 €***

Suggested retail price: ~~185.00 €*~~

Promotion!



U-WAVE fit, Buzzer Type

Wireless Transmitter for Caliper
Art No. 264-621

Promo price: **129.00 €***

Suggested retail price: ~~185.00 €*~~

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, Straight,
with Data Button

Art No. 06AFM380C

Promo price: **98.90 €***

Suggested retail price: ~~124.00 €*~~



Digimatic Cable, Straight, Data Button,

1m

Art No. 959149

Suggested retail price: ~~48.00 €*~~



Digimatic Cable, Straight, Data Button

2m

 
Art No. 959150

Suggested retail price: ~~57.00 €*~~



Depth Base Attachment for Caliper

75mm width for 100, 150, 200mm Range
Art No. 050083-10
Suggested retail price: 60.00 €*



Depth Base Attachment for Caliper

100mm width for 100, 150, 200mm Range
Art No. 050084-10
Suggested retail price: 67.00 €*



Data Hold Unit

for Digital Caliper
Art No. 959143
Suggested retail price: 36.00 €*

Promotion!

Mitutoyo

MiCAT

the standard in world
metrology software
MeasurLink®

USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available
Online)

Art No. 06AGR543

Promo price: **259.00 €***

Suggested retail price: ~~340.00 €*~~

A red USB dongle with a white label that reads "USB-ITPAK".

USB-ITPAK

Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 10.00 €*
