

Digital ABS Caliper

Item number: 500-500-10

Images



ABSOLUTE®

Description


This digimatic caliper allows you to take reliable measurements and offers you the following benefits:

- It has a robust design (6 x 25 mm beam) for large measuring ranges.
- ABSOLUTE System delivers reliable measurements.
- The slider provides smooth, stable and comfortable operation.
- Character height: 10 mm.

Features

Model:	CD-45C
Range:	0 - 450 mm
Delivered:	Including SR44 battery
Max. Permissible Error E MPE:	±0,05 mm
Max. Permissible Error S MPE:	±0,07 mm
Digital step:	0,01 mm
Max. response speed:	Unlimited
Display:	LCD, character height 10 mm
ORIGIN (ABS-Zero):	Yes
ON/OFF:	Yes
Low voltage alarm:	Yes
Data output:	Yes
Battery life:	Approx. 20000 hours
Mass:	1170 g

Dimensions

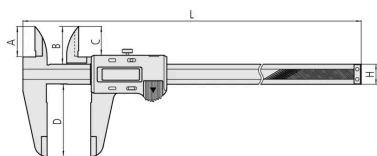

L: 630 mm

A: 38 mm

B: 47 mm

C: 35.9 mm

D: 90 mm

H: 25 mm

Accessories

Optional accessories:



Digimatic Cable, Straight, Data Button,

1m
Art No. 959149
Suggested retail price: 48.00 €*



Digimatic Cable, Straight, Data Button

2m
Art No. 959150
Suggested retail price: 57.00 €*



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, Straight,
with Data Button
Art No. 06AFM380C
Suggested retail price: 124.00 €*



U-WAVE-T, IP67 Type

Wireless Transmitter
Art No. 02AZD730G
Suggested retail price: 187.00 €*



U-WAVE-T, Buzzer Type

Wireless Transmitter
Art No. 02AZD880G
Suggested retail price: 187.00 €*



Connection Cable C for U-WAVE

Straight, with Data Button
Art No. 02AZD790C
Suggested retail price: 105.00 €*



Data Hold Unit

for Digital Caliper
Art No. 959143
Suggested retail price: 39.50 €*

Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882
Suggested retail price: 7.00 €*