

Digital ABS Caliper CoolantProof IP67

Item number: 500-707-20

Images



Description

This IP67 ABSOLUTE digimatic caliper allows reliable measurements in a wide range of situations and offers you the following benefits:


- Excellent resistance against water and dust (IP67 protection level) enabling use in machining situations that include splashing coolant fluid
- It is dustproof, complies with EN60529 and withstands temporary complete immersion in water without suffering any damage.
- ABS (ABSOLUTE) scale requires no origin setting after power-on and has no limit to response speed.

Features

Model:	CD-P20P
Range:	0 - 200 mm
Delivered:	Including box, SR44 battery, certificate of inspection
Depth bar:	flat
Data output:	No
Max. Permissible Error E MPE:	±0,02 mm

Max. Permissible Error S MPE:	±0,04 mm
Digital step:	0,01 mm
Max. response speed:	Unlimited
Display:	LCD, character height 9 mm (150, 200 mm) 11 mm (300 mm)
ORIGIN (ABS-Zero):	Yes
Auto Power OFF after 20 min. non use:	Yes
Low voltage alarm:	Yes
Battery life:	Approx. 5 years under normal use
Mass:	198 g

Dimensions

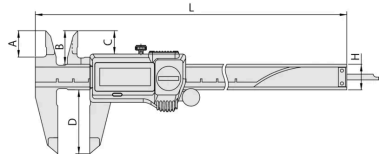

L: 290 mm

A: 20 mm

B: 24.5 mm


C: 18.1 mm

D: 50 mm

H: 16 mm


Accessories

Optional accessories:

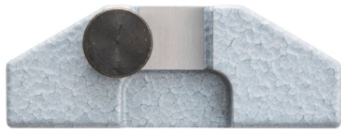

Depth Base Attachment for Caliper

 75mm width for 100, 150, 200mm Range
Art No. 050083-10
Suggested retail price: **60.00 €***



Depth Base Attachment for Caliper

100mm width for 100, 150, 200mm Range
Art No. 050084-10
Suggested retail price: **67.00 €***

Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 7.00 €*
