


Digital ABS Caliper CoolantProof IP67

Item number: 500-718-20

Images

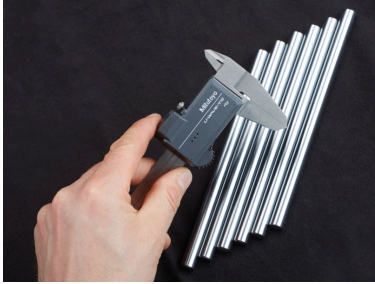

Dust- and
Water-
Protected

www.tuv.com
ID 000045042

ABSOLUTE®



IP67

Description

This IP67 ABSOLUTE digimatic caliper allows reliable measurements in a wide range of situations and offers you the following benefits:

- Excellent resistance against water and dust (IP67 protection level) enabling use in machining situations that include splashing coolant fluid
- It is dustproof, complies with EN60529 and withstands temporary complete immersion in water without suffering any damage.
- ABS (ABSOLUTE) scale requires no origin setting after power-on and has no limit to response speed.

Features

Model:	CD-P30K
Delivered:	Including box, SR44 battery, certificate of inspection
Range:	0 - 300 mm
Depth bar:	flat
Data output:	Yes
Max. Permissible Error E MPE:	±0,03 mm
Max. Permissible Error S MPE:	±0,05 mm
Digital step:	0,01 mm
Max. response speed:	Unlimited
Display:	LCD, character height 9 mm (150, 200 mm) 11 mm (300 mm)
ORIGIN (ABS-Zero):	Yes
Auto Power OFF after 20 min. non use:	Yes
Low voltage alarm:	Yes
Battery life:	Approx. 5 years under normal use
Mass:	345 g

Dimensions

Accessories

Optional accessories:

Promotion!

Mitutoyo

MiCAT
the standard in world
metrology software
measurLink


USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available Online)

Art No. 06AGR543

Promo price: 259.00 €*

Suggested retail price: ~~340.00 €*~~

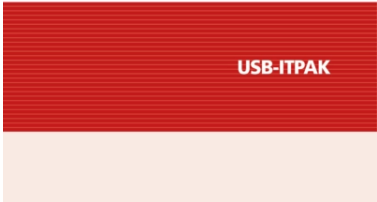



Digimatic Cable with Data Button IP Type

1m, Caliper Type
Art No. 05CZA624
Suggested retail price: 100.00 €*



Digimatic Cable with Data Button IP Type

2m, Caliper Type
Art No. 05CZA625
Suggested retail price: 107.00 €*

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, with Data Button IP Caliper Type
Art No. 06AFM380A
Promo price: **109.00 €***
Suggested retail price: ~~141.00 €*~~

Promotion!



U-WAVE fit, IP67 Type

Wireless Transmitter for Caliper
Art No. 264-620
Promo price: **129.00 €***
Suggested retail price: ~~185.00 €*~~

Promotion!



U-WAVE fit, Buzzer Type

Wireless Transmitter for Caliper
Art No. 264-621
Promo price: **129.00 €***
Suggested retail price: ~~185.00 €*~~

Promotion!



U-WAVE fit Bluetooth, IP67 Type

Wireless Transmitter for Caliper
Art No. 264-624
Promo price: **139.00 €***
Suggested retail price: ~~185.00 €*~~

Promotion!



U-WAVE fit Bluetooth, Buzzer Type

Wireless Transmitter for Caliper
Art No. 264-625

Promo price: **139.00 €***
Suggested retail price: ~~185.00 €*~~

Promotion!



Connection Unit for IP Caliper, Micrometer

with Data Button for U-WAVE fit, U-WAVE fit Bluetooth

Art No. 02AZF310
Promo price: **74.90 €***
Suggested retail price: ~~110.00 €*~~

Depth Base Attachment for Caliper



125mm width for 300mm Range
Art No. 050085-10
Suggested retail price: **74.00 €***

Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882
Suggested retail price: **10.00 €***