

Digital ABS Caliper CoolantProof IP67

Item number: 500-721-20

Images



Dust- and
Water-
Protected

www.tuv.com
ID 0000045042

ABSOLUTE®



Description

These robust calipers have carbide-tipped jaws and allow reliable measurements in a wide range of situations.

The ABSOLUTE Digimatic Carbide Caliper IP67 offers you the following benefits:


- Excellent resistance against water and dust (IP67 protection level) enabling use in machining situations that include splashing coolant fluid.
- Dustproof, complies with EN60529 withstands temporary complete immersion in water without suffering any damage
- Extraordinarily long battery life.

Features

Model:	CD-P15MW
Delivered:	Including box, SR44 battery, certificate of inspection
Range:	0 - 150 mm
Depth bar:	flat
Thumb roller:	Yes
Data output:	Yes

Max. Permissible Error E MPE:	±0,02 mm
Max. Permissible Error S MPE:	±0,04 mm
Digital step:	0,01 mm
Max. response speed:	Unlimited
Display:	LCD, character height 9 mm
ORIGIN (ABS-Zero):	Yes
Auto Power OFF after 20 min. non use:	Yes
Low voltage alarm:	Yes
Battery life:	Approx. 5 years under normal use
Mass:	168 g

Dimensions

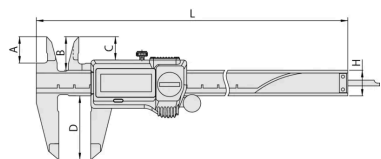

L: 233 mm

A: 16.5 mm

B: 21 mm

C: 14.6 mm

D: 40 mm


H: 16 mm

Accessories

Optional accessories:

Promotion!





the standard in world metrology software




USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available Online)

Art No. 06AGR543

Promo price: **259.00 €***

~~Suggested retail price: 340.00 €*~~

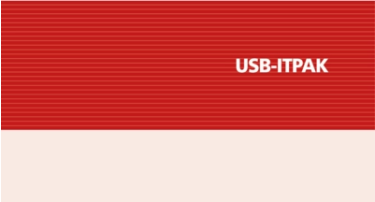



Digimatic Cable with Data Button IP Type

1m, Caliper Type
 Art No. 05CZA624
 Suggested retail price: 100.00 €*



Digimatic Cable with Data Button IP Type

2m, Caliper Type
Art No. 05CZA625
Suggested retail price: 107.00 €*
Suggested retail price: 107.00 €*

Promotion!



Connection Cable A for U-WAVE

with Data Button for IP Caliper Type
Art No. 02AZD790A
Promo price: 72.90 €*
Suggested retail price: 110.00 €*

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, with Data Button IP Caliper Type
Art No. 06AFM380A
Promo price: 109.00 €*
Suggested retail price: 141.00 €*

Promotion!



U-WAVE fit, IP67 Type

Wireless Transmitter for Caliper
Art No. 264-620
Promo price: 129.00 €*
Suggested retail price: 185.00 €*

Promotion!



U-WAVE fit, Buzzer Type

Wireless Transmitter for Caliper
Art No. 264-621
Promo price: 129.00 €*
Suggested retail price: 185.00 €*

Promotion!



U-WAVE fit Bluetooth, IP67 Type

Wireless Transmitter for Caliper
Art No. 264-624

Promo price: **139.00 €***
Suggested retail price: ~~185.00 €*~~

Promotion!



U-WAVE fit Bluetooth, Buzzer Type

Wireless Transmitter for Caliper
Art No. 264-625

Promo price: **139.00 €***
Suggested retail price: ~~185.00 €*~~

Promotion!



Connection Unit for IP Caliper, Micrometer

 
with Data Button for U-WAVE fit, U-WAVE fit Bluetooth
Art No. 02AZF310

Promo price: **74.90 €***
Suggested retail price: ~~110.00 €*~~



Depth Base Attachment for Caliper

75mm width for 100, 150, 200mm Range
Art No. 050083-10
Suggested retail price: **60.00 €***



Depth Base Attachment for Caliper

100mm width for 100, 150, 200mm Range
Art No. 050084-10
Suggested retail price: **67.00 €***

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 10.00 €*
