 


## Digital ABS Caliper CoolantProof IP67

Item number: 500-728-20

### Images



Dust- and  
Water-  
Protected

www.tuv.com  
ID 0000045042

# ABSOLUTE®



# IP67

### Description

These robust calipers have carbide-tipped jaws and allow reliable measurements in a wide range of situations.

The ABSOLUTE Digimatic Carbide Caliper IP67 offers you the following benefits:

- Excellent resistance against water and dust (IP67 protection level) enabling use in machining situations that include splashing coolant fluid.
- Dustproof, complies with EN60529 withstands temporary complete immersion in water without suffering any damage
- Extraordinarily long battery life.

### Features

#### Delivered:

Including box, SR44 battery, certificate of inspection

<b>Range:</b>	0 - 200 mm
<b>Depth bar:</b>	flat
<b>Data output:</b>	Yes
<b>Max. Permissible Error E MPE:</b>	±0,02 mm
<b>Max. Permissible Error S MPE:</b>	±0,04 mm
<b>Digital step:</b>	0,01 mm
<b>Max. response speed:</b>	Unlimited
<b>Display:</b>	LCD, character height 9 mm
<b>ORIGIN (ABS-Zero):</b>	Yes
<b>Auto Power OFF after 20 min. non use:</b>	Yes
<b>Low voltage alarm:</b>	Yes
<b>Battery life:</b>	Approx. 5 years under normal use
<b>Mass:</b>	194 g

## Dimensions

## Accessories

### Optional accessories:

Promotion!

**Mitutoyo**

**MiCAT**  
the standard in world  
metrology software  
**MeasurLink**


**USB-ITPAK Vers. 3.0**

USB Dongle + Manual (Software available Online)

Art No. 06AGR543

**Promo price: 259.00 €\***

~~Suggested retail price: 340.00 €\*~~

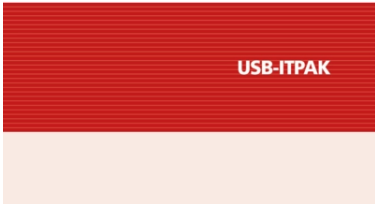



### Digimatic Cable with Data Button IP Type

1m, Caliper Type  
Art No. 05CZA624  
Suggested retail price: 100.00 €\*



## Digimatic Cable with Data Button IP Type

2m, Caliper Type  
Art No. 05CZA625  
Suggested retail price: 107.00 €\*  
Suggested retail price: 107.00 €\*  
Suggested retail price: 107.00 €\*

Promotion!



## Connection Cable A for U-WAVE

with Data Button for IP Caliper Type  
Art No. 02AZD790A  
Promo price: 72.90 €\*  
Suggested retail price: 110.00 €\*

Promotion!



## USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, with Data Button IP Caliper Type  
Art No. 06AFM380A  
Promo price: 109.00 €\*  
Suggested retail price: 141.00 €\*

Promotion!



## U-WAVE fit, IP67 Type

Wireless Transmitter for Caliper  
Art No. 264-620  
Promo price: 129.00 €\*  
Suggested retail price: 185.00 €\*

Promotion!



## U-WAVE fit, Buzzer Type

Wireless Transmitter for Caliper  
Art No. 264-621  
Promo price: 129.00 €\*  
Suggested retail price: 185.00 €\*

Promotion!



### U-WAVE fit Bluetooth, IP67 Type

Wireless Transmitter for Caliper  
Art No. 264-624

Promo price: **139.00 €\***  
Suggested retail price: ~~185.00 €\*~~

Promotion!



### U-WAVE fit Bluetooth, Buzzer Type

Wireless Transmitter for Caliper  
Art No. 264-625

Promo price: **139.00 €\***  
Suggested retail price: ~~185.00 €\*~~

Promotion!



### Connection Unit for IP Caliper, Micrometer

 
with Data Button for U-WAVE fit, U-WAVE fit Bluetooth  
Art No. 02AZF310

Promo price: **74.90 €\***  
Suggested retail price: ~~110.00 €\*~~



### Depth Base Attachment for Caliper

75mm width for 100, 150, 200mm Range  
Art No. 050083-10  
Suggested retail price: **60.00 €\***



### Depth Base Attachment for Caliper

100mm width for 100, 150, 200mm Range  
Art No. 050084-10  
Suggested retail price: **67.00 €\***

Consumable spares:

---



**Battery SR44 1,5 V**

Art No. 938882

Suggested retail price: 10.00 €\*  

---