

## Digital ABS Caliper CoolantProof IP67

Item number: 500-735-20

### Images



# ABSOLUTE®



# IP67

### Description

These robust calipers have carbide-tipped jaws and allow reliable measurements in a wide range of situations.

The ABSOLUTE Digimatic Carbide Caliper IP67 offers you the following benefits:


- Excellent resistance against water and dust (IP67 protection level) enabling use in machining situations that include splashing coolant fluid.
- Dustproof, complies with EN60529 withstands temporary complete immersion in water without suffering any damage
- Extraordinarily long battery life.

### Features

<b>Range:</b>	0 - 6 "
<b>Delivered:</b>	Including box, SR44 battery, certificate of inspection
<b>Depth bar:</b>	flat
<b>Thumb roller:</b>	Yes
<b>Data output:</b>	Yes
<b>Max. Permissible Error E MPE:</b>	±0.001"

<b>Max. Permissible Error S MPE:</b>	±0.002"
<b>Digital step:</b>	0.0005"/0.01 mm
<b>Max. response speed:</b>	Unlimited
<b>Display:</b>	LCD, character height 9 mm (150, 200 mm) 11 mm (300 mm)
<b>ORIGIN (ABS-Zero):</b>	Yes
<b>Auto Power OFF after 20 min. non use:</b>	Yes
<b>Low voltage alarm:</b>	Yes
<b>Battery life:</b>	Approx. 5 years under normal use
<b>Mass:</b>	168 g

## Dimensions

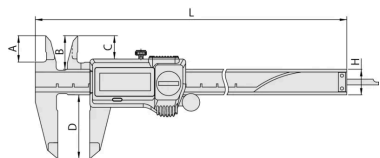

**L:** 233 mm mm

**A:** 16.5 mm

**B:** 21 mm

**C:** 14.6 mm

**D:** 40 mm

**H:** 16 mm

## Accessories

### Optional accessories:



### Connection Unit for IP Caliper, Micrometer

with Data Button for U-WAVE fit, U-WAVE fit Bluetooth

Art No. 02AZF310

Suggested retail price: 110.00 €\*



### Connection Cable A for U-WAVE

with Data Button for IP Caliper Type

Art No. 02AZD790A

Suggested retail price: 110.00 €\*



### **USB Input Tool Direct (Digimatic to USB)**

2m Cable, Digimatic/Digimatic 2, with Data  
Button IP Caliper Type  
Art No. 06AFM380A  
Suggested retail price: 141.00 €\*  

---



### **Digimatic Cable with Data Button IP Type**

1m, Caliper Type  
Art No. 05CZA624  
Suggested retail price: 100.00 €\*  

---



### **U-WAVE fit Bluetooth, IP67 Type**

Wireless Transmitter for Caliper  
Art No. 264-624  
Suggested retail price: 185.00 €\*  

---



### **U-WAVE fit Bluetooth, Buzzer Type**

Wireless Transmitter for Caliper  
Art No. 264-625  
Suggested retail price: 185.00 €\*  

---



### **Digimatic Cable with Data Button IP Type**

2m, Caliper Type  
Art No. 05CZA625  
Suggested retail price: 107.00 €\*  

---



### U-WAVE fit, IP67 Type

Wireless Transmitter for Caliper  
Art No. 264-620  
Suggested retail price: 185.00 €\*  

 
---



### Depth Base Attachment for Caliper

75mm width for 100, 150, 200mm Range  
Art No. 050083-10  
Suggested retail price: 60.00 €\*  

---



### Depth Base Attachment for Caliper

100mm width for 100, 150, 200mm Range  
Art No. 050084-10  
Suggested retail price: 67.00 €\*  

---


Mitutoyo

MiCAT  
the standard in world  
metrology software  
measurLink

### USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available  
Online)  
Art No. 06AGR543  
Suggested retail price: 340.00 €\*  

---

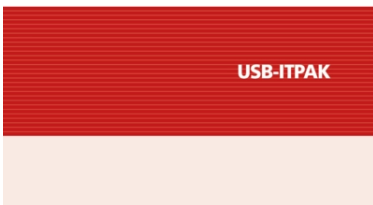

### Spare parts

Consumable spares:



## Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 7.00 €\*  

---