 


Digital ABS Caliper CoolantProof IP67

Item number: 500-753-20

Images



Dust- and
Water-
Protected

www.tuv.com
ID 0000045042

ABSOLUTE®



Description

This IP67 ABSOLUTE digimatic caliper allows reliable measurements in a wide range of situations and offers you the following benefits:


- Excellent resistance against water and dust (IP67 protection level) enabling use in machining situations that include splashing coolant fluid
- It is dustproof, complies with EN60529 and withstands temporary complete immersion in water without suffering any damage.
- ABS (ABSOLUTE) scale requires no origin setting after power-on and has no limit to response speed.

Features

Model:	CD-P8"S
Range:	0 - 8 "
Delivered:	Including box, SR44 battery, certificate of inspection
Depth bar:	flat
Thumb roller:	Yes
Data output:	No

Max. Permissible Error E MPE:	±0.001"
Max. Permissible Error S MPE:	±0.002"
Digital step:	0.0005"/0.01 mm
Max. response speed:	Unlimited
Display:	LCD, character height 9 mm (150, 200 mm) 11 mm (300 mm)
ORIGIN (ABS-Zero):	Yes
Auto Power OFF after 20 min. non use:	Yes
Low voltage alarm:	Yes
Battery life:	Approx. 5 years under normal use
Mass:	194 g

Dimensions

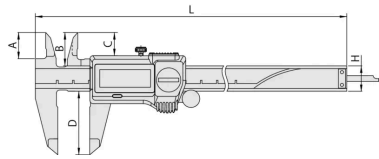

L: 290 mm

A: 20 mm

B: 24.5 mm


C: 18.1 mm

D: 50 mm

H: 16 mm


Accessories

Optional accessories:

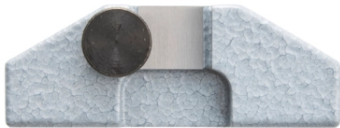

Depth Base Attachment for Caliper

 75mm width for 100, 150, 200mm Range
Art No. 050083-10
Suggested retail price: 60.00 €*



Depth Base Attachment for Caliper

100mm width for 100, 150, 200mm Range
Art No. 050084-10
Suggested retail price: 67.00 €*

Standard accessories:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 7.00 €*

Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 7.00 €*
