

Digital ABS Caliper CoolantProof IP67

Item number: 500-754-20

Images



Dust- and
Water-
Protected

www.tuv.com
ID 0000045042

ABSOLUTE®



Description

This IP67 ABSOLUTE digimatic caliper allows reliable measurements in a wide range of situations and offers you the following benefits:

- Excellent resistance against water and dust (IP67 protection level) enabling use in machining situations that include splashing coolant fluid
- It is dustproof, complies with EN60529 and withstands temporary complete immersion in water without suffering any damage.
- ABS (ABSOLUTE) scale requires no origin setting after power-on and has no limit to response speed.

Features

Model:	CD-P12"S
Range:	0 - 12 "
Delivered:	Including box, SR44 battery, certificate of inspection
Depth bar:	flat
Thumb roller:	Yes
Data output:	No

Max. Permissible Error E MPE: ±0,0015"

Max. Permissible Error S MPE: ±0,0025"

Digital step: 0.0005"/0.01 mm

Max. response speed: Unlimited

Display: LCD, character height 9 mm (150, 200 mm)
11 mm (300 mm)

ORIGIN (ABS-Zero): Yes


Auto Power OFF after 20 min. non use: Yes

Low voltage alarm: Yes

Battery life: Approx. 5 years under normal use

Mass: 345 g

Dimensions

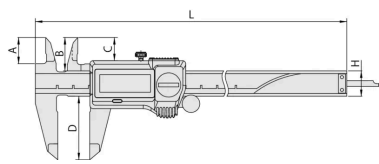

L: 404 mm

A: 22 mm

B: 27.5 mm

C: 19.8 mm

D: 64 mm

H: 20 mm

Accessories

Standard accessories:



Depth Base Attachment for Caliper

125mm width for 300mm Range
Art No. 050085-10
Suggested retail price: 74.00 €*

Spare parts

Consumable spares:

button battery
Art No. ED002
Price on application



Battery SR44 1,5 V

Art No. 938882
Suggested retail price: 7.00 €*
