


Digital ABS Caliper CoolantProof IP67

Item number: 500-769-20

Images

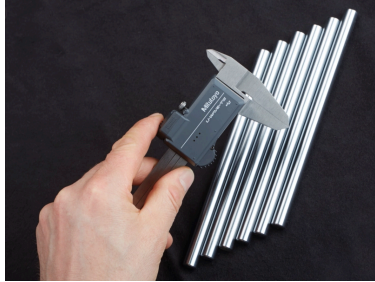

Dust- and
Water-
Protected

www.tuv.com
ID 0000045042

ABSOLUTE®



IP67

Description

This IP67 ABSOLUTE digimatic caliper allows reliable measurements in a wide range of situations and offers you the following benefits:

- Excellent resistance against water and dust (IP67 protection level) enabling use in machining situations that include splashing coolant fluid
- It is dustproof, complies with EN60529 and withstands temporary complete immersion in water without suffering any damage.
- ABS (ABSOLUTE) scale requires no origin setting after power-on and has no limit to response speed.

Features

Model:

CD-P6"MR

| | |
|--|--|
| Range: | 0 - 6 " |
| Delivered: | Including box, SR44 battery, certificate of inspection |
| Depth bar: | Ø 1.9 mm |
| Thumb roller: | Yes |
| Data output: | Yes |
| Max. Permissible Error E MPE: | ±0.001" |
| Max. Permissible Error S MPE: | ±0.002" |
| Digital step: | 0.0005"/0.01 mm |
| Max. response speed: | Unlimited |
| Display: | LCD, character height 9 mm (150, 200 mm) 11 mm (300 mm) |
| ORIGIN (ABS-Zero): | Yes |
| Auto Power OFF after 20 min. non use: | Yes |
| Low voltage alarm: | Yes |
| Battery life: | Approx. 5 years under normal use |
| Mass: | 164 g |

Dimensions

Accessories

Optional accessories:



U-WAVE fit Bluetooth, IP67 Type

Wireless Transmitter for Caliper
Art No. 264-624
Suggested retail price: 185.00 €*



U-WAVE fit Bluetooth, Buzzer Type

Wireless Transmitter for Caliper
Art No. 264-625
Suggested retail price: 185.00 €*

USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available Online)

Art No. 06AGR543

Suggested retail price: 340.00 €*



USB-ITPAK

Digimatic Cable with Data Button IP Type



1m, Caliper Type

Art No. 05CZA624

Suggested retail price: 100.00 €*

Digimatic Cable with Data Button IP Type



2m, Caliper Type

Art No. 05CZA625

Suggested retail price: 107.00 €*

Connection Cable A for U-WAVE



with Data Button for IP Caliper Type

Art No. 02AZD790A

Suggested retail price: 110.00 €*

USB Input Tool Direct (Digimatic to USB)



2m Cable, Digimatic/Digimatic 2, with Data Button IP Caliper Type

Art No. 06AFM380A

Suggested retail price: 141.00 €*



Connection Unit for IP Caliper, Micrometer

with Data Button for U-WAVE fit, U-WAVE fit
Bluetooth

Art No. 02AZF310

Suggested retail price: 110.00 €*



U-WAVE fit, IP67 Type

Wireless Transmitter for Caliper

Art No. 264-620

Suggested retail price: 185.00 €*

 


Depth Base Attachment for Caliper

75mm width for 100, 150, 200mm Range

Art No. 050083-10

Suggested retail price: 60.00 €*



Depth Base Attachment for Caliper

100mm width for 100, 150, 200mm Range

Art No. 050084-10

Suggested retail price: 67.00 €*

Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 7.00 €*
