

Dial Caliper ID/OD Carbide Tipped Jaws

Item number: 505-735

Images



Description


These dial calipers allows you to take reliable measurements and offers you the following benefits:

- Ultra-smooth sliding and high shock protection.
- Easy to read dial with large character height.

Features

Range:	0 - 150 mm
Graduation:	0,02 mm 2mm/rev
Delivered:	Including plastic box
Depth bar:	flat
Max. Permissible Error E MPE:	$\pm 0,03$ mm
Max. Permissible Error S MPE:	$\pm 0,05$ mm
Mass:	175 g

Dimensions

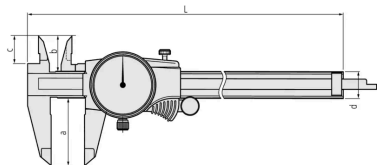

a: 40 mm

b: 21 mm

c: 16.5 mm

d: 16 mm

 
Accessories

Optional accessories:



Depth Base Attachment for Caliper

75mm width for 100, 150, 200mm Range
Art No. 050083-10
Suggested retail price: 60.00 €*



Depth Base Attachment for Caliper

100mm width for 100, 150, 200mm Range
Art No. 050084-10
Suggested retail price: 67.00 €*
