
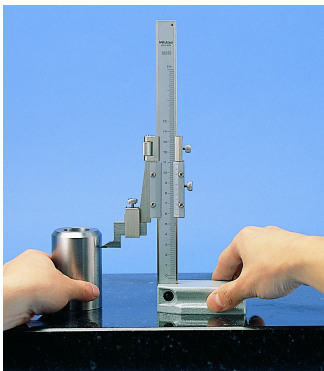
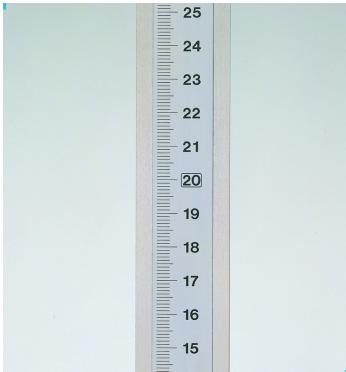


## Vernier Height Gauge

Item number: 506-207

### Images

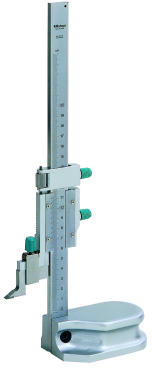

### Description

This vernier height gauge offers you the following benefits:

- You can take accurate and fast readings thanks to the satin chrome finished main and vernier scales.
- A carbide-tipped scriber is provided.


### Features

Digital/Analog:

Analog


<b>Range:</b>	0 - 200 mm
<b>Graduation:</b>	0,02 mm
<b>Delivered:</b>	Including carbide tipped scriber, scriber clamp
<b>Max. Permissible Error E MPE:</b>	±0,03 mm
<b>Fine adjustment:</b>	4 mm
<b>Scale adjustment:</b>	15 mm: 300, 450, 600 mm range, 25 mm: 1000 mm range
<b>Inch-Metric:</b>	Metric
<b>Mass:</b>	1.4 kg

## Dimensions

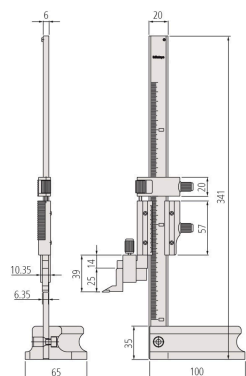

## Accessories

### Optional accessories:

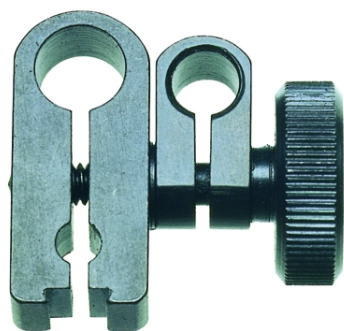

### Swivel Clamp

for D= 4/8mm, Dovetail

Art No. 900321

Suggested retail price: 26.50 €\*

### Holding Bar for Swivel Clamp

6,25x12,7mm, 2" Length

Art No. 953639

Suggested retail price: 19.50 €\*



## Center Master



for 6,35x12,7mm  
Art No. 900581  
Suggested retail price: 161.00 €\*  

---

## Depth Gauge Attachment



for 12,7mm x 6,35mm  
Art No. 900878  
Suggested retail price: 59.00 €\*  

---

## Contact Sensor



for Height Gauges  
Art No. 900872  
Suggested retail price: 135.00 €\*  

---

Standard accessories:

---

## Scriber Clamp with Plastic Screw



for 12,7x6,35mm Scriber  
Art No. 06AGR304  
Price on application  

---

## Carbide Tipped Scriber



6,35x12,7mm, 47mm Length  
Art No. 900173  
Suggested retail price: 87.00 €\*  

---

