


## Vernier Height Gauge

Item number: 506-208

### Images

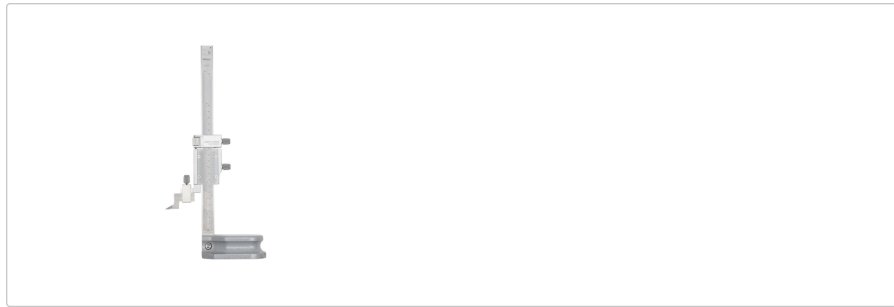

### Description

A Mitutoyo vernier height gauge with a dual unit main scale. Stainless steel construction with easy-to-read, satin-chromed scales.

### Features

<b>Digital/Analog:</b>	Analog
<b>Range:</b>	0 - 8 "
<b>Graduation:</b>	0.001"/0.02 mm
<b>Delivered:</b>	Including carbide tipped scriber, scriber clamp
<b>Max. Permissible Error E MPE:</b>	$\pm 0,001"/\pm 0,03$ mm
<b>Max. Permissible Error J MPE:</b>	$\pm 0.03$ mm/0.001"
<b>Scale adjustment:</b>	15 mm: 300, 450, 600 mm range, 25 mm: 1000 mm range
<b>Inch-Metric:</b>	Inch/Metric
<b>Mass:</b>	1.4 kg

### Accessories

Optional accessories:




#### Holding Bar for Swivel Clamp

6,25x12,7mm, 2" Length

Art No. 953639

Suggested retail price: 19.50 €\*

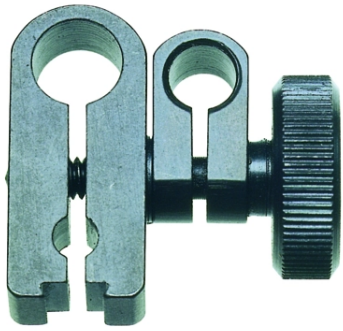

### Swivel Clamp

for D= 4/8mm, Dovetail  
Art No. 900321  
Suggested retail price: 26.50 €\*  

---



### Center Master

for 6,35x12,7mm  
Art No. 900581  
Suggested retail price: 161.00 €\*  

---



### Depth Gauge Attachment

for 12,7mm x 6,35mm  
Art No. 900878  
Suggested retail price: 59.00 €\*  

---



### Contact Sensor

for Height Gauges  
Art No. 900872  
Suggested retail price: 135.00 €\*  

---

Standard accessories:



### **Scriber Clamp with Plastic Screw**

for 12,7x6,35mm Scriber

Art No. 07GZA004

Price on application



### **Carbide Tipped Scriber**

6,35x12,7mm, 47mm Length

Art No. 900173

Suggested retail price: 87.00 €\*