

Indicating Micrometer with Button Left

Item number: 510-132

Images



Description


A Mitutoyo non-digital, rapid-retraction-anvil indicating micrometer equipped with a high resolution dial indicator.

Features

Digital/Analog:	Analog
Inch-Metric:	Inch
Range:	1 - 2 "
Delivered:	Including box, spanner, setting standard
Indicating range:	$\pm 0.0023''$
Anvil retracting stroke:	2 mm

Spindle feed error:	0.00015 inch
Accuracy dial comparator:	1 μ m
Repeatability:	0.00002"
Flatness:	0,3 μ m
Parallelism:	0.000024"
Graduation:	0.0001"
Measuring face:	Carbide-tipped, micro-lap finish, \varnothing 8 mm
Measuring spindle:	With spindle lock, \varnothing 8 mm, spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish, \varnothing 21 mm
Measuring force:	5 - 10 N
Operating button:	Left
Mass:	670 g

Dimensions

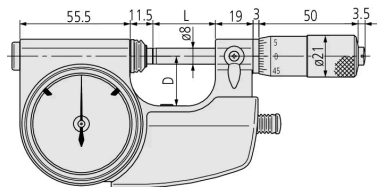

L: 56.5 mm

D: 38 inch

Accessories

Optional accessories:



Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"

Art No. 156-101-10

Promo price: **56.00 €***

Suggested retail price: ~~70.00 €*~~



Workpiece Stopper Indicating Micrometer

23mm

Art No. 04AZA124

Suggested retail price: **20.80 €***



Workpiece Stopper Indicating Micrometer

20,5mm

Art No. 04AZA125

Suggested retail price: 20.80 €*




Workpiece Stopper Indicating Micrometer

15mm

Art No. 04AZA126

Suggested retail price: 20.80 €*

Standard accessories:

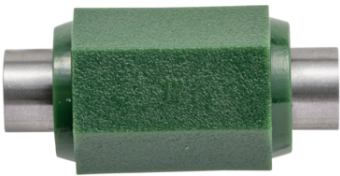

Micrometer Setting Standard

Length: 1"

Art No. 167-141

Suggested retail price: 33.00 €*
