

## Indicating Micrometer with Button Left

Item number: 510-134

### Images



### Description


A Mitutoyo non-digital, rapid-retraction-anvil indicating micrometer equipped with a high resolution dial indicator.

### Features

<b>Digital/Analog:</b>	Analog
<b>Inch-Metric:</b>	Inch
<b>Range:</b>	3 - 4 "
<b>Delivered:</b>	Including box, spanner, setting standard
<b>Indicating range:</b>	$\pm 0.0023''$

<b>Anvil retracting stroke:</b>	2 mm
<b>Spindle feed error:</b>	0.00015 inch
<b>Accuracy dial comparator:</b>	1 $\mu\text{m}$
<b>Repeatability:</b>	0.00002"
<b>Flatness:</b>	0,3 $\mu\text{m}$
<b>Parallelism:</b>	0.00004"
<b>Graduation:</b>	0.0001"
<b>Measuring face:</b>	Carbide-tipped, micro-lap finish, $\varnothing 8$ mm
<b>Measuring spindle:</b>	With spindle lock, $\varnothing 8$ mm, spindle pitch 0,5 mm
<b>Scale:</b>	Thimble and sleeve satin chrome finish, $\varnothing 21$ mm
<b>Measuring force:</b>	5 - 10 N
<b>Operating button:</b>	Left
<b>Mass:</b>	970 g

#### Dimensions

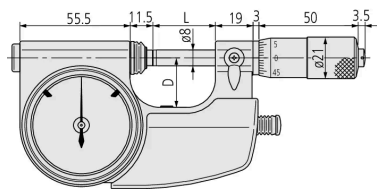

**L:** 106.5 mm

**D:** 63 inch

#### Accessories

Optional accessories:



#### Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"  
Art No. 156-101-10

**Promo price: 56.00 €\***

~~Suggested retail price: 70.00 €\*~~



#### Workpiece Stopper Indicating Micrometer

23mm

Art No. 04AZA124

Suggested retail price: 20.80 €\*



### Workpiece Stopper Indicating Micrometer

20,5mm

Art No. 04AZA125

Suggested retail price: 20.80 €\*  

---



### Workpiece Stopper Indicating Micrometer

15mm

Art No. 04AZA126

Suggested retail price: 20.80 €\*  

---

#### Standard accessories:

---



### Micrometer Setting Standard

Length: 3"

Art No. 167-143

Suggested retail price: 37.00 €\*  

---