

2-Point Inside Measuring Instrument

Item number: 511-207-20

Images



Description

These are bore gauges that automatically self-centre via a centring bridge. They offer you the following benefits:

- A long plunger stroke gives you amazing accuracy.
- Interchangeable washers 0.5 mm thick are supplied as standard accessories, so you can enable setting in small steps.
- Contact points are carbide (>18 mm range), giving you high durability and wear resistance.
- A large grip reduces heat transfer from the operator by 50%.


Features

| | |
|---------------------------------|--|
| Inch-Metric: | Inch |
| Digital/Analog: | Analog |
| Range: | 0.4 - 0.74 " |
| Graduation: | 0.0005" |
| Stroke of contact point: | 0.6 mm |
| Measuring depth: | 4" |
| No. Dial Indicator: | 2922AB |
| Number of anvils: | 9 |
| Accuracy: | 5 μ m |
| Repeatability: | 2 μ m |
| Measuring force: | \leq 2 N |
| Delivered: | In a box with bore gauge 511-205, dial indicator 2922AB, plastic cover for |

indicator 21DZA000, 9 anvils, 1 interchangeable washer

Mass: 252 g

Dimensions

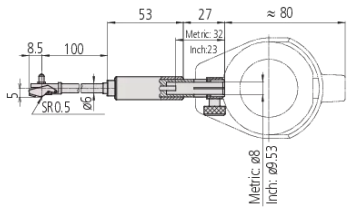

Accessories

Optional accessories:



Digital Indicator, Bore Gauge ID-C

ASME/ANSI Type, Inch/Metric, 0,5", 0,00005", Flat Back Plate
Art No. 543-312B-10
Suggested retail price: 563.00 €*

Limit Hands (green) 2pcs



Dial Indicator Series 2/3/4
Art No. 21AZB195
Price on application

Standard accessories:



Anvil 10-11mm/511

Art No. 204356
Price on application



Anvil 11-12mm/511

Art No. 204357

Price on application



Anvil 12-13mm/511

Art No. 204358

Price on application



Anvil 13-14mm/511

Art No. 204359

Price on application



Anvil 14-15mm/526

Art No. 204360

Price on application



Anvil 15-16mm/511

Art No. 204361

Price on application



Anvil 16-17mm/511

Art No. 204362

Price on application



Anvil 17-18mm/511

Art No. 204363

Price on application



Anvil 18-18.5mm/511

Art No. 204364

Price on application



Washer (0.5mm)/511

Art No. 204355

Price on application



Spanner/511

Art No. 204354

Price on application



Dial Gauge, Flat Back, ANSI/AGD Type

0,125", 0,0005"
Art No. 2922AB
Suggested retail price: 107.00 €*



2-Point Inside Measuring Instrument

Bore Gauge, 0,4-0,74", w/o Indicator
Art No. 511-205
Suggested retail price: 487.00 €*



Protector for Indicator (plastic cover)

Art No. 21DZA000
Suggested retail price: 20.00 €*