

## 2-Point Inside Measuring Instrument

Item number: 511-212-20

### Images



### Description


These are bore gauges that automatically self-centre via a centring bridge. They offer you the following benefits:

- A long plunger stroke gives you amazing accuracy.
- Interchangeable washers 0.5 mm thick are supplied as standard accessories, so you can enable setting in small steps.
- Contact points are carbide (>18 mm range), giving you high durability and wear resistance.
- A large grip reduces heat transfer from the operator by 50%.

### Features

<b>Inch-Metric:</b>	Inch
<b>Digital/Analog:</b>	Analog
<b>Range:</b>	0.24 - 0.4 "
<b>Graduation:</b>	0.0001"
<b>Stroke of contact point:</b>	0.5 mm
<b>Measuring depth:</b>	2"
<b>No. Dial Indicator:</b>	2923AB-10
<b>Number of anvils:</b>	9
<b>Accuracy:</b>	5 $\mu$ m
<b>Repeatability:</b>	2 $\mu$ m
<b>Measuring force:</b>	$\leq$ 2 N
<b>Delivered:</b>	In a box with bore gauge 511-214, dial indicator 2923AB-10, plastic cover for indicator 21DZA000, 9 anvils
<b>Mass:</b>	260 g

### Dimensions

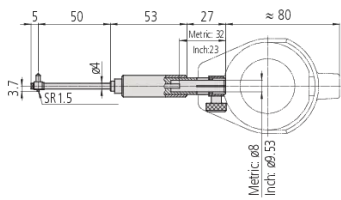

## Accessories

### Optional accessories:



### Digital Indicator, Bore Gauge ID-C

ASME/ANSI Type, Inch/Metric, 0,5", 0,00005", Flat Back Plate

Art No. 543-312B-10

Suggested retail price: 563.00 €\*



### Limit Hands (green) 2pcs

Dial Indicator Series 2/3/4

Art No. 21AZB195

Price on application

### Standard accessories:



### Anvil (6 mm)/511

Small Holes Type, 6 mm/0,24 "

Art No. 952168

Price on application



### **Anvil (6.5mm)/511**

Art No. 952169

Price on application



### **Anvil (7mm)/511**

Art No. 952170

Price on application



### **Anvil (7.5mm)/511**

Art No. 952414

Price on application



### **Anvil (8mm)/511**

Art No. 952415

Price on application



### **Anvil (8.5mm)/511**

Art No. 952416

Price on application

### Anvil (9MM)/511

Art No. 952417

Price on application



### Anvil (9.5mm)/511

Art No. 952418

Price on application



### Anvil (10mm)/511

Art No. 952419

Price on application




206709

### Spanner/511

Art No. 206709

Price on application

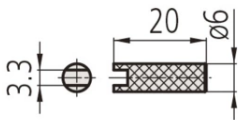

### Tweezers/511

Art No. 206710


Price on application





## Dial Gauge, Flat Back, ANSI/AGD Type

Jewelled Bearing, Shockproof, 0,05", 0,0001"  
Art No. 2923AB-10  
Suggested retail price: 145.00 €\*

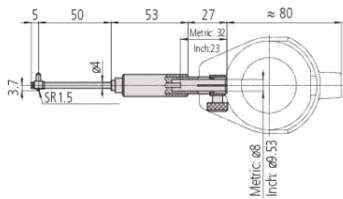

## 2-Point Inside Measuring Instrument

Bore Gauge, 0,24-0,4", w/o Indicator  
Art No. 511-214  
Suggested retail price: 436.00 €\*



## Protector for Indicator (plastic cover)

Art No. 21DZA000  
Suggested retail price: 20.00 €\*