


2-Point Inside Measuring Instrument

Item number: 511-713-20

Images

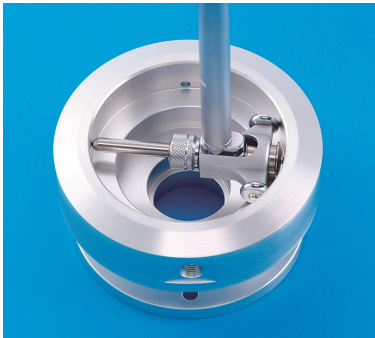

Description

This is a short range application Bore Gauge Set that automatically self-centres via a centring bridge and offers you the following benefits:


- It reduces the influence of heat from the operator's hand by 50% by making the grip hollow structured, thereby retaining high accuracy measurement.
- Interchangeable washers (0,5 mm thick) are supplied as standard accessories, so you can enable setting in small steps.
- Contact points are carbide (>18 mm range), giving you high durability and wear resistance.

Features

Inch-Metric:	Metric
Range:	50 - 150 mm

Graduation:	0.01 mm
Stroke of contact point:	1.6 mm
Measuring depth:	150 mm
No. Dial Indicator:	2046AB
Number of anvils:	11
Accuracy:	2 µm
Repeatability:	0.5 µm
Digital/Analog:	Analog
Delivered:	In a box with bore gauge 511-703, dial indicator 2046AB, plastic cover for indicator 21DZA000, 11 anvils, 4 interchangeable washer, 1 sub-anvil
Mass:	420 g


Dimensions

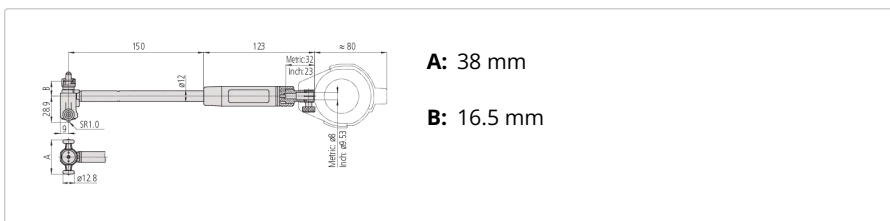


Accessories

Optional accessories:

Extension Rod Serie 511

125mm, 12mm Rod Diameter
Art No. 953552
Suggested retail price: 251.00 €*


Extension Rod Serie 511

250mm, 12mm Rod Diameter
Art No. 953553
Suggested retail price: 275.00 €*


Extension Rod Serie 511

500mm, 12mm Rod Diameter
Art No. 953554
Suggested retail price: 493.00 €*



Extension Rod Serie 511

750mm, 12mm Rod Diameter
Art No. 953555
Suggested retail price: 655.00 €*



Extension Rod Serie 511

1000mm, 12mm Rod Diameter
Art No. 953556
Suggested retail price: 907.00 €*



Digital Indicator, Bore Gauge ID-C

12,7mm, 0,001mm, Flat Back Plate
Art No. 543-310B-10
Suggested retail price: 563.00 €*



Limit Hands (green) 2pcs

Dial Indicator Series 2/3/4
Art No. 21AZB195
Price on application





**Carbide Tipped Anvil Series
511**

Range 50mm (100mm)
Art No. 21DZA232A
Suggested retail price: 13.00 €*



**Carbide Tipped Anvil Series
511**

Range 40mm, 55mm (105mm)
Art No. 21DZA232B
Suggested retail price: 13.00 €*



**Carbide Tipped Anvil Series
511**

Range 45mm, 60mm (110mm)
Art No. 21DZA232C
Suggested retail price: 13.00 €*



**Carbide Tipped Anvil Series
511**

Range 50mm, 65mm (115mm)
Art No. 21DZA232D
Suggested retail price: 13.00 €*



**Carbide Tipped Anvil Series
511**

Range 55mm, 70mm (120mm)
Art No. 21DZA232E
Suggested retail price: 13.00 €*



Carbide Tipped Anvil Series 511

Range 60mm, 75mm (125mm)
Art No. 21DZA232F
Suggested retail price: 13.00 €*



Carbide Tipped Anvil Series 511

Range 80mm (130mm)
Art No. 21DZA232G
Suggested retail price: 15.00 €*



Carbide Tipped Anvil Series 511

Range 85mm (135mm)
Art No. 21DZA232H
Suggested retail price: 15.00 €*



Carbide Tipped Anvil Series 511

Range 90mm (140mm)
Art No. 21DZA232J
Suggested retail price: 16.00 €*



Carbide Tipped Anvil Series 511

Range 95mm (145mm)
Art No. 21DZA232L
Suggested retail price: 16.00 €*



Carbide Tipped Anvil Series 511

Range 100mm (150mm)
Art No. 21DZA232M
Suggested retail price: 16.00 €*



Washer Series 511

0,5mm, Range 35-160mm
Art No. 205457
Suggested retail price: 7.00 €*



Washer Series 511

1 mm, Range 35-160mm
Art No. 205458
Suggested retail price: 7.00 €*




Washer Series 511

2 mm, Range 35-160mm
Art No. 205459
Suggested retail price: 7.00 €*



Washer Series 511

3 mm, Range 35-160mm
Art No. 205460
Suggested retail price: 7.00 €*

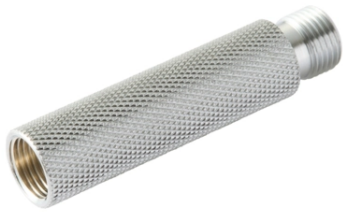

Sub-Anvil Series 511

50 mm
Art No. 102178
Suggested retail price: 24.00 €*



2-Point Inside Measuring Instrument

Bore Gauge, 50-150mm, w/o Indicator
Art No. 511-703
Suggested retail price: 310.00 €*

Promotion!



Dial Gauge, Flat Back, ISO Type

10mm, 0,01mm
Art No. 2046AB
**Promo price: 37.90 €*
Suggested retail price: 48.00 €***



Protector for Indicator (plastic cover)

Art No. 21DZA000
Suggested retail price: 20.00 €*
