
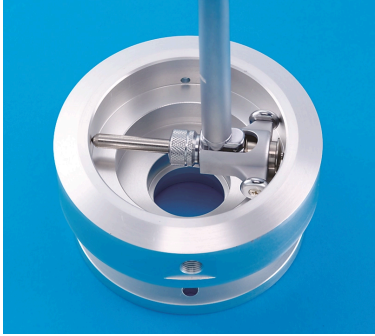


2-Point Inside Measuring Instrument

Item number: 511-745-20

Images

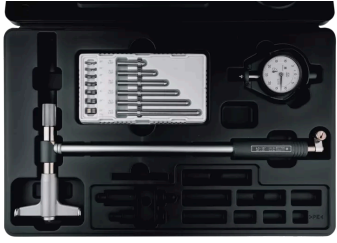

Description

This is a short range application Bore Gauge Set that automatically self-centres via a centring bridge and offers you the following benefits:

- It reduces the influence of heat from the operator's hand by 50% by making the grip hollow structured, thereby retaining high accuracy measurement.
- Interchangeable washers (0,5 mm thick) are supplied as standard accessories, so you can enable setting in small steps.
- Contact points are carbide (>18 mm range), giving you high durability and wear resistance.

Features

Inch-Metric:	Inch
Range:	6.5 - 10 "
Graduation:	0.0005"

Stroke of contact point:	18 - 60 mm: 1.2 mm 50 - 400 mm: 1.6 mm
---------------------------------	---

Measuring depth:	10"
-------------------------	-----

No. Dial Indicator:	2922AB
----------------------------	--------

Number of anvils:	6
--------------------------	---

Accuracy:	2 μm
------------------	-----------------


Repeatability:	0.5 μm
-----------------------	-------------------

Digital/Analog:	Analog
------------------------	--------

Delivered:	In a box with bore gauge 511-735, dial indicator 2922B, plastic cover for indicator 21DZA000, 6 anvils, 7 interchangeable washer
-------------------	--

Mass:	850 g
--------------	-------

Dimensions

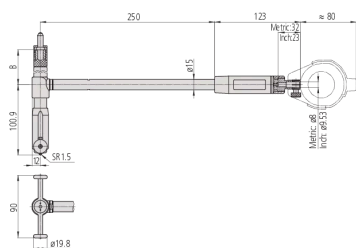

B: 55.1 mm

Accessories

Optional accessories:



Digital Indicator, Bore Gauge ID-C

ASME/ANSI Type, Inch/Metric, 0,5", 0,00005",
Flat Back Plate
Art No. 543-312B-10
Suggested retail price: 563.00 €*

Limit Hands (green) 2pcs

Dial Indicator Series 2/3/4
Art No. 21AZB195

Price on application



Extension Rod Serie 511

250mm, 9mm Rod Diameter
Art No. 953550
Suggested retail price: 257.00 €*



Extension Rod Serie 511

250mm, 15mm Rod Diameter
Art No. 952361
Suggested retail price: 264.00 €*



Extension Rod Serie 511

500mm, 15mm Rod Diameter
Art No. 953558
Suggested retail price: 622.00 €*



Extension Rod Serie 511

750mm, 15mm Rod Diameter
Art No. 953559
Suggested retail price: 815.00 €*



Extension Rod Serie 511

1000mm, 15mm Rod Diameter
Art No. 953560
Suggested retail price: 1,070.00 €*



Standard accessories:



Anvil No.1

511-705...-736
Art No. 21DZA241A
Price on application



Anvil No.2/511

511-705...-736
Art No. 21DZA241B
Price on application



Anvil No.3/511

511-705...-736
Art No. 21DZA241C
Price on application



Anvil No.4/511

511-705...-736
Art No. 21DZA241D
Price on application



Anvil No.5/511

511-705...-736
Art No. 21DZA241E
Price on application




Anvil No.6/511

511-705...-736

Art No. 21DZA241F

Price on application

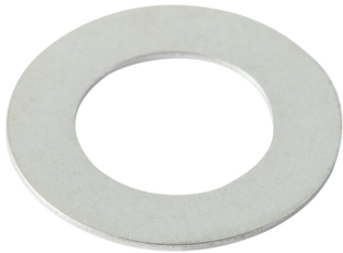

Washer 0.5mm 0.02"/511

0.5mm / .02"

Art No. 205467

Price on application



Washer /511

1 mm / .04"

Art No. 205461

Price on application



Washer /511

2mm / .08"

Art No. 205462

Price on application



Washer 3mm 0.12"/511

3mm / .12"

Art No. 205463

Price on application



Washer /511

4 mm
Art No. 205464
Price on application



Washer /511

5 mm
Art No. 205465
Price on application



Washer /511

6 mm
Art No. 205466
Price on application



2-Point Inside Measuring Instrument

Bore Gauge, 6,5-10", w/o Indicator
Art No. 511-735
Suggested retail price: 599.00 €*
*Suggested retail price is for informational purposes only and does not include taxes and shipping.



Dial Gauge, Flat Back, ANSI/AGD Type

0,125", 0,0005"
Art No. 2922AB
Suggested retail price: 107.00 €*
*Suggested retail price is for informational purposes only and does not include taxes and shipping.



Protector for Indicator (plastic cover)

Art No. 21DZA000

Suggested retail price: 20.00 €*
