

2-Point Inside Measuring Instrument

Item number: 511-793-20

Images



Description

This is a compact and lightweight bore gauge due to the short length below the grip. It offers you the following benefits:

- A long plunger stroke gives you amazing accuracy.
- Contact points are carbide giving you high durability and wear resistance.
- A large grip reduces heat transfer from the operator by 50%.


Features

Inch-Metric:	Inch
Range:	2 - 6 "
Graduation:	0.0001"
Stroke of contact point:	18 - 60 mm: 1.2 mm 50 - 160 mm: 1.6 mm
Measuring depth:	2"
No. Dial Indicator:	2923AB-10
Number of anvils:	11
Accuracy:	2 μ m
Repeatability:	0.5 μ m
Digital/Analog:	Analog
Delivered:	In a box with bore gauge 511-783, dial indicator 2923AB-10, plastic cover for indicator 21DZA000, 11 anvils, 4 interchangeable washer, 1 sub-anvil

Mass:

400 g

Dimensions

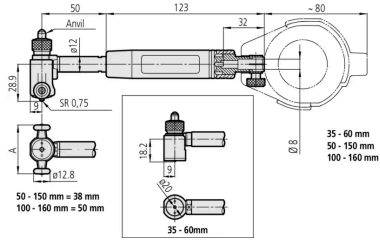

Accessories

Optional accessories:



Limit Hands (green) 2pcs

Dial Indicator Series 2/3/4

Art No. 21AZB195

Price on application



Digital Indicator, Bore Gauge ID-C

ASME/ANSI Type, Inch/Metric, 0,5", 0,00005", Flat Back Plate

Art No. 543-312B-10

Suggested retail price: 563.00 €*

Standard accessories:



Photo Not Available

2-Point Inside Measuring Instrument

Bore Gauge for Short Length, 2-6", w/o Indicator

Art No. 511-783

Suggested retail price: 295.00 €*



Dial Gauge, Flat Back, ANSI/AGD Type

Jewelled Bearing, Shockproof, 0,05", 0,0001"
Art No. 2923AB-10
Suggested retail price: 145.00 €*



Protector for Indicator (plastic cover)

Art No. 21DZA000
Suggested retail price: 20.00 €*



Carbide Tipped Anvil Series 511

Range 50mm (100mm)
Art No. 21DZA232A
Suggested retail price: 13.00 €*



Carbide Tipped Anvil Series 511

Range 40mm, 55mm (105mm)
Art No. 21DZA232B
Suggested retail price: 13.00 €*



Carbide Tipped Anvil Series 511

Range 45mm, 60mm (110mm)
Art No. 21DZA232C
Suggested retail price: 13.00 €*

Carbide Tipped Anvil Series 511



Range 50mm, 65mm (115mm)
Art No. 21DZA232D
Suggested retail price: 13.00 €*

Carbide Tipped Anvil Series 511



Range 55mm, 70mm (120mm)
Art No. 21DZA232E
Suggested retail price: 13.00 €*

Carbide Tipped Anvil Series 511



Range 60mm, 75mm (125mm)
Art No. 21DZA232F
Suggested retail price: 13.00 €*

Carbide Tipped Anvil Series 511



Range 80mm (130mm)
Art No. 21DZA232G
Suggested retail price: 15.00 €*

Carbide Tipped Anvil Series 511



Range 85mm (135mm)
Art No. 21DZA232H
Suggested retail price: 15.00 €*



Carbide Tipped Anvil Series 511

Range 90mm (140mm)
Art No. 21DZA232J
Suggested retail price: 16.00 €*



Carbide Tipped Anvil Series 511

Range 95mm (145mm)
Art No. 21DZA232L
Suggested retail price: 16.00 €*



Carbide Tipped Anvil Series 511

Range 100mm (150mm)
Art No. 21DZA232M
Suggested retail price: 16.00 €*



Washer Series 511

0,5mm, Range 35-160mm
Art No. 205457
Suggested retail price: 7.00 €*



Washer Series 511

1 mm, Range 35-160mm
Art No. 205458
Suggested retail price: 7.00 €*




Washer Series 511

2 mm, Range 35-160mm
Art No. 205459
Suggested retail price: 7.00 €*



Washer Series 511

3 mm, Range 35-160mm
Art No. 205460
Suggested retail price: 7.00 €*

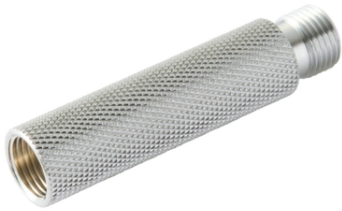

Sub-Anvil Series 511

50 mm
Art No. 102178
Suggested retail price: 24.00 €*