

2-Point Inside Measuring Instrument

Item number: 511-794-20

Images



Description

This is a compact and lightweight bore gauge due to the short length below the grip. It offers you the following benefits:

- A long plunger stroke gives you amazing accuracy.
- Contact points are carbide giving you high durability and wear resistance.
- A large grip reduces heat transfer from the operator by 50%.


Features

| | |
|---------------------------------|---|
| Inch-Metric: | Inch |
| Range: | 4 - 6.5 " |
| Graduation: | 0.0001" |
| Stroke of contact point: | 18 - 60 mm: 1.2 mm 50 - 160 mm: 1.6 mm |
| Measuring depth: | 2" |
| No. Dial Indicator: | 2923AB-10 |
| Number of anvils: | 13 |
| Accuracy: | 2 μ m |
| Repeatability: | 0.5 μ m |
| Digital/Analog: | Analog |
| Delivered: | In a box with bore gauge 511-784, dial indicator 2923AB-10, plastic cover for indicator 21DZA000, 13 anvils, 4 interchangeable washer |

Mass:

460 g

Dimensions

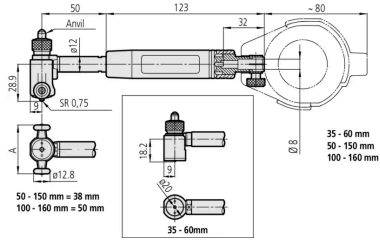

Accessories

Optional accessories:



Limit Hands (green) 2pcs

Dial Indicator Series 2/3/4

Art No. 21AZB195

Price on application



Digital Indicator, Bore Gauge ID-C

ASME/ANSI Type, Inch/Metric, 0,5", 0,00005", Flat Back Plate

Art No. 543-312B-10

Suggested retail price: 563.00 €*

Standard accessories:



Photo Not Available

2-Point Inside Measuring Instrument

Bore Gauge for Short Length, 4-6,5, w/o Indicator

Art No. 511-784

Suggested retail price: 425.00 €*



Dial Gauge, Flat Back, ANSI/AGD Type

Jewelled Bearing, Shockproof, 0,05", 0,0001"
Art No. 2923AB-10
Suggested retail price: 145.00 €*



Protector for Indicator (plastic cover)

Art No. 21DZA000
Suggested retail price: 20.00 €*



Carbide Tipped Anvil Series 511

Range 50mm (100mm)
Art No. 21DZA232A
Suggested retail price: 13.00 €*



Carbide Tipped Anvil Series 511

Range 40mm, 55mm (105mm)
Art No. 21DZA232B
Suggested retail price: 13.00 €*



Carbide Tipped Anvil Series 511

Range 45mm, 60mm (110mm)
Art No. 21DZA232C
Suggested retail price: 13.00 €*

Carbide Tipped Anvil Series 511



Range 50mm, 65mm (115mm)
Art No. 21DZA232D
Suggested retail price: 13.00 €*

Carbide Tipped Anvil Series 511



Range 55mm, 70mm (120mm)
Art No. 21DZA232E
Suggested retail price: 13.00 €*

Carbide Tipped Anvil Series 511



Range 60mm, 75mm (125mm)
Art No. 21DZA232F
Suggested retail price: 13.00 €*

Carbide Tipped Anvil Series 511



Range 80mm (130mm)
Art No. 21DZA232G
Suggested retail price: 15.00 €*

Carbide Tipped Anvil Series 511



Range 85mm (135mm)
Art No. 21DZA232H
Suggested retail price: 15.00 €*



Carbide Tipped Anvil Series 511

Range 90mm (140mm)
Art No. 21DZA232J
Suggested retail price: 16.00 €*



Carbide Tipped Anvil Series 511

Range 95mm (145mm)
Art No. 21DZA232L
Suggested retail price: 16.00 €*



Carbide Tipped Anvil Series 511

Range 100mm (150mm)
Art No. 21DZA232M
Suggested retail price: 16.00 €*



Carbide Tipped Anvil Series 511

Range 155mm
Art No. 21DZA232N
Price on application



Carbide Tipped Anvil Series 511

Range 160mm
Art No. 21DZA232P
Price on application



Washer Series 511

0,5mm, Range 35-160mm
Art No. 205457
Suggested retail price: 7.00 €*



Washer Series 511

1 mm, Range 35-160mm
Art No. 205458
Suggested retail price: 7.00 €*



Washer Series 511

2 mm, Range 35-160mm
Art No. 205459
Suggested retail price: 7.00 €*



Washer Series 511

3 mm, Range 35-160mm
Art No. 205460
Suggested retail price: 7.00 €*
