


Dial Test Indicator, Universal Type

Item number: 513-302-10T

Images

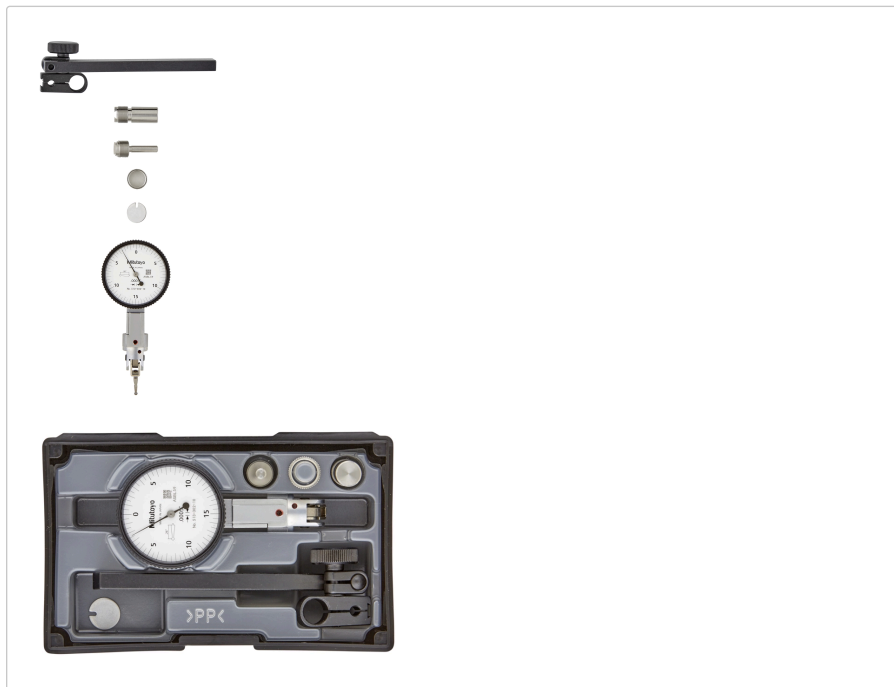

Description


This is a Dial Test Indicator (Lever Type) which offers you the following benefits:

- Drastically enhanced durability, sensitivity and visibility.
- Glare-free flat crystal face allows easy reading of graduations.
- O-ring seal on the bezel has the effect of providing smooth rotation and prevents dust and oil from penetrating through to the dial face.
- The stylus length is on the dial face to reorder a replacement
- Multi-layer coatings on the crystal.

Features

Digital/Analog:	Analog
Inch-Metric:	Inch
Range:	0,03 "
Dial reading:	0-15-0
Delivered:	In a box with stem $\varnothing 3/8$ " (9,52 mm)/0,157" (4 mm), stylus $\varnothing 0,039$ "/0,079" (2 pcs,)/0,118", swivel clamp and holding bar, spanner
Graduation:	0,0005"
H MPE (Hysteresis):	0.0003"
R MPE (Repeatability):	± 0.0003 "
MPE first one revolution:	± 0.0005 "
Measuring force:	0,01-0,3 N
Contact point:	Thread M 1.4 x 0.3
Remarks:	Full set
Mass:	71 g

Dimensions

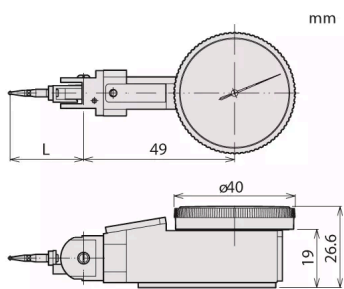

Accessories

Optional accessories:



Limit Hands (Green) 2 pcs.

Dial Indicator Series 1, Test Indicator

Art No. 21AAB363

Price on application

Standard accessories:



Stem for Standard Type Series 513

D=4mm

Art No. 21CAB106

Suggested retail price: 9.80 €*



Stem for Standard Type Series 513

D=8mm

Art No. 21CAB104

Suggested retail price: 6.50 €*

Knurled Clamp Ring for Stem

Lever Indicator Serie 513
Art No. 190322
Suggested retail price: 5.80 €*



Stylus for Serie 513

D= 1mm, 6,5mm Length, Carbide
Art No. 102824
Suggested retail price: 7.30 €*



Stylus for Serie 513

D= 2mm, 6,5mm Length, Carbide
Art No. 102825
Suggested retail price: 14.50 €*



Stylus for Serie 513

D= 3mm, 6,5mm Length, Carbide
Art No. 102826
Suggested retail price: 7.30 €*



Swivel Clamp

for D= 4/9,52mm, Dovetail
Art No. 900322
Suggested retail price: 26.50 €*



Holding Bar for Swivel Clamp

12,7x6,35mm, 4" Length
Art No. 900306
Suggested retail price: 17.30 €*



Spanner

Serie 513
Art No. 102037
Suggested retail price: 2.80 €*

