


Dial Test Indicator, Horizontal Type

Item number: 513-426-10A

Images

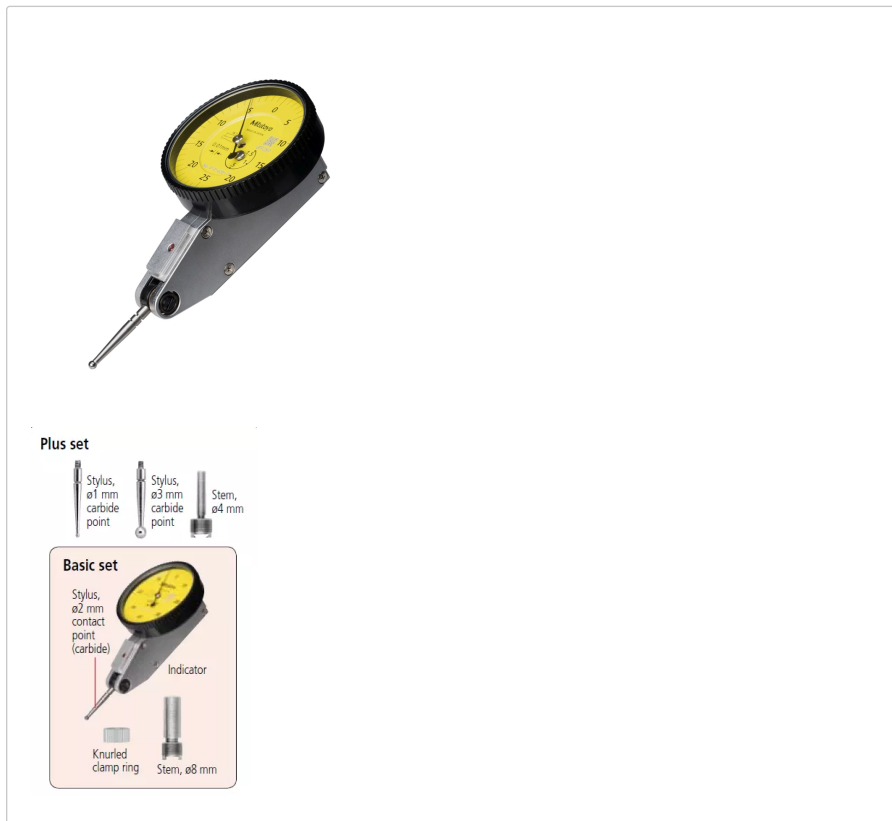

Description

This is a Dial Test Indicator (Lever Type) which offers you the following benefits:

- Drastically enhanced durability, sensitivity and visibility.
- Glare-free flat crystal face allows easy reading of graduations.
- O-ring seal on the bezel has the effect of providing smooth rotation and prevents dust and oil from penetrating through to the dial face.
- The stylus length is on the dial face to reorder a replacement
- Multi-layer coatings on the crystal.

Features


Digital/Analog:	Analog
Inch-Metric:	Metric
Delivered:	In a box with stem $\varnothing 8/4$ mm, stylus $\varnothing 1/2/3$ mm
Range:	1.5 mm
Graduation:	0.01 mm
MPE any 10 scale divisions:	5 μ m
MPE any 1 revolution:	10 μ m
MPE measuring range:	16 μ m
H MPE (Hysteresis):	4 μ m
R MPE (Repeatability):	3 μ m
Carbide stylus tip $\varnothing 2$ mm No.:	137557

Mass: 45 g

Contact point: Thread M 1.7 x 0.35

Remarks: Plus set

Dimensions

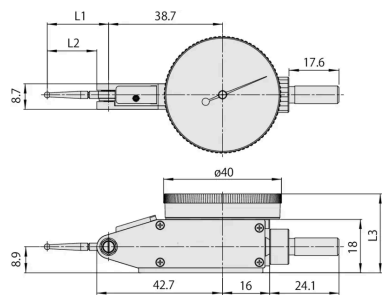

L1: 22.2 mm

L2: 18.7 mm

L3: 27.5 mm

D Ø: 40 mm

Accessories

Optional accessories:



Limit Hands (Green) 2 pcs.

Dial Indicator Series 1, Test Indicator

Art No. 21AAB363

Price on application

Standard accessories:



Stem for Standard Type Series 513

D=4mm

Art No. 21CAB106

Suggested retail price: 15.00 €*



Stem for Standard Type Series 513

D=8mm

Art No. 21CAB104

Suggested retail price: 15.00 €*



Stylus for Serie 513

D= 1mm, 18,7mm Length, Carbide
Art No. 137558
Suggested retail price: 16.00 €*



Stylus for Serie 513

D= 2mm, 18,7mm Length, Carbide
Art No. 137557
Suggested retail price: 21.00 €*



Stylus for Serie 513

D= 3mm, 18,7mm Length, Carbide
Art No. 137559
Suggested retail price: 16.00 €*



Knurled Clamp Ring for Stem

Lever Indicator Serie 513
Art No. 190322
Suggested retail price: 12.00 €*