


Dial Test Indicator, Horiz. 20° Face

Item number: 513-442-16A

Images

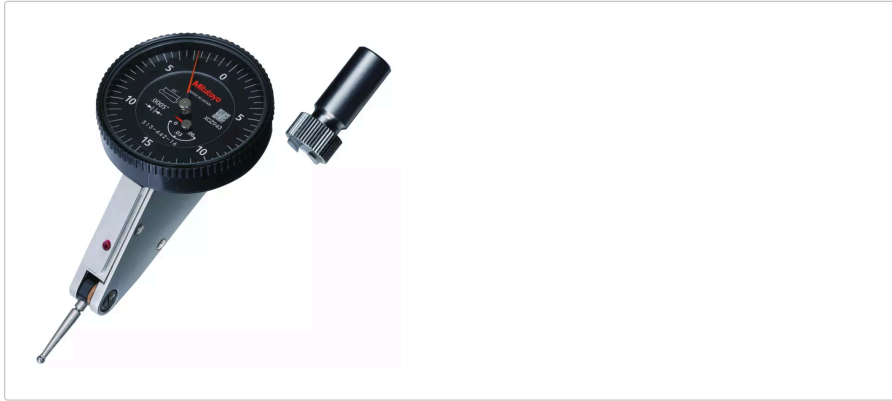

Description

This is a Dial Test Indicator (Lever Type) which offers you the following benefits:

- Drastically enhanced durability, sensitivity and visibility.
- Glare-free flat crystal face allows easy reading of graduations.
- O-ring seal on the bezel has the effect of providing smooth rotation and prevents dust and oil from penetrating through to the dial face.
- The stylus length is on the dial face to reorder a replacement
- Multi-layer coatings on the crystal.

Features

Digital/Analog:	Analog
Inch-Metric:	Inch
Range:	0,06 "
Dial reading:	0-15-0
Delivered:	In a box with stem $\varnothing 3/8$ " (9.52 mm) / 0.157" (4 mm), stylus $\varnothing 0.039$ "/0.079"/0.118"
Graduation:	0.0005"
H MPE (Hysteresis):	0.0002"
R MPE (Repeatability):	± 0.0002 "
MPE first one revolution:	± 0.0005 "
MPE first 2 1/2 revolutions:	± 0.0005 "
Measuring force:	0,01-0,3 N
Contact point:	Thread M 1.7 x 0.35
Remarks:	Plus set
Mass:	48 g

Accessories

Optional accessories:



Limit Hands (Green) 2 pcs.

Dial Indicator Series 1, Test Indicator

Art No. 21AAB363

Price on application

Standard accessories:



Stylus for Series 513

Ø 2mm, 19,9mm (16,4mm) length, Carbide

Art No. 133195

Price on application



Stem for Standard Type Series 513

D=4mm

Art No. 21CAB106

Suggested retail price: 9.80 €*



Stylus for Series 513

Ø0,04", 0,79" length, Steel

Art No. 133196

Suggested retail price: 7.30 €*



Art No. 21CAB105

Suggested retail price: 10.50 €*

Stylus for Series 513

Ã 0,12",0,79" length, Steel
Art No. 133197
Suggested retail price: 7.30 €*



Knurled Clamp Ring for Stem

Lever Indicator Serie 513
Art No. 190322
Suggested retail price: 5.80 €*



Spare parts

Consumable spares:

Stylus for Series 513

Ø 2mm, 19,9mm (16,4mm) length, Carbide
Art No. 133195
Price on application

