


Dial Test Indicator, Horiz. 20° Face

Item number: 513-443-16T

Images

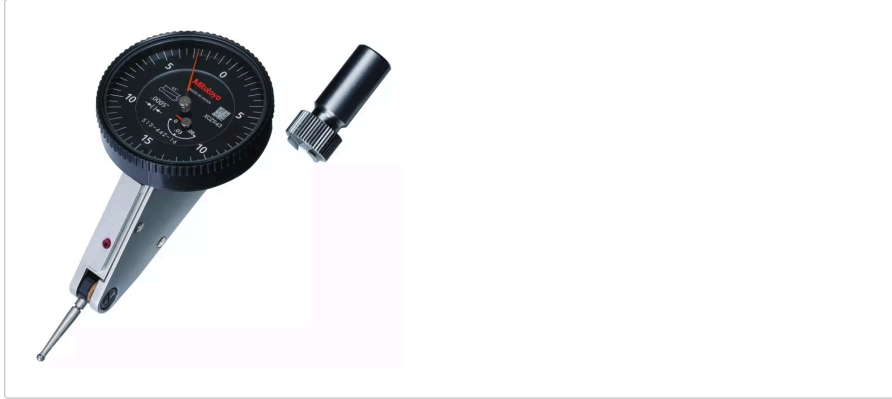

Description

This is a Dial Test Indicator (Lever Type) which offers you the following benefits:

- Drastically enhanced durability, sensitivity and visibility.
- Glare-free flat crystal face allows easy reading of graduations.
- O-ring seal on the bezel has the effect of providing smooth rotation and prevents dust and oil from penetrating through to the dial face.
- The stylus length is on the dial face to reorder a replacement
- Multi-layer coatings on the crystal.

Features

Digital/Analog:	Analog
Inch-Metric:	Inch
Range:	0,016 "
Dial reading:	0-4-0
Delivered:	In a box with stem $\varnothing 3/8$ " (9.52 mm) / 0.157" (4 mm), stylus $\varnothing 0.039$ "/0.079"/0.118", swivel clamp / holding bar
Graduation:	0.0001"
H MPE (Hysteresis):	0.0001"
R MPE (Repeatability):	± 0.00004 "
MPE first one revolution:	± 0.0002 "
MPE first 2 1/2 revolutions:	± 0.0002 "
Measuring force:	0,01-0,3 N
Contact point:	Thread M 1.7 x 0.35
Remarks:	Full set
Mass:	48 g

Accessories

Optional accessories:



Limit Hands (Green) 2 pcs.

Dial Indicator Series 1, Test Indicator

Art No. 21AAB363

Price on application

Standard accessories:



Art No. 21CZB064

Suggested retail price: 8.40 €*
Price on application



Stem for Standard Type Series 513

D=4mm

Art No. 21CAB106

Suggested retail price: 9.80 €*
Price on application



Art No. 901162

Price on application



Art No. 21CAB105

Suggested retail price: 10.50 €*
Price on application

Art No. 21CZB065
Suggested retail price: 7.40 €*



Art No. 21CZB066
Suggested retail price: 8.40 €*



Knurled Clamp Ring for Stem

Lever Indicator Serie 513
Art No. 190322
Suggested retail price: 5.80 €*

